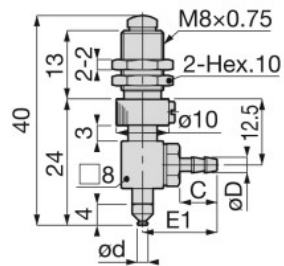
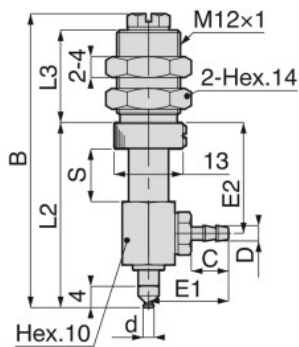


VPD スプリング式 真空取出口：横、バース継手内蔵スタンダードタイプ

単位：mm

VPD1-3R 5 6 9
VPD2-3R 5 6 9
VPD3-3R 5 6 9
VPD4-3R 5 6 9

 パッド
 接続記号
-H3

VPD1 3 R 5 6 9
VPD2 3 R 5 6 9
VPD3 3 R 5 6 9
VPD4 3 R 5 6 9

 パッド
 接続記号
-H3

 ストローク(mm)
 3, 10, 15, 20

形式	パッド外径 d	チューブ内径 D	B	L2	L3	C	E1	E2	ストローク S	スプリング力 (N)		
VPD1-3R5-3B9	1	2	—	—	—	6	12.4	—	3	0.9~1.9		
VPD1-3R5-4B9		2.5				7	13.9				3	0.9~1.9
VPD1-3R5-6B9		4				7	13.9					
VPD1-10R5-3B		2	55.6	35	17.5	6	13.4	21	10	0.6~1.7		
VPD1-10R5-4B		2.5				7	14.9					
VPD1-10R5-6B		4				7	14.9					
VPD1-15R5-3B		2	66.6	40	23.5	6	13.4	26	15	0.4~1.7		
VPD1-15R5-4B		2.5				7	14.9					
VPD1-15R5-6B		4				7	14.9					
VPD1-20R5-3B		2	76.6	45	28.5	6	13.4	31	20	0.3~1.8		
VPD1-20R5-4B		2.5				7	14.9					
VPD1-20R5-6B		4				7	14.9					
VPD2-3R5-3B9	2	2	—	—	—	6	12.4	—	3	0.9~1.9		
VPD2-3R5-4B9		2.5				7	13.9				3	0.9~1.9
VPD2-3R5-6B9		4				7	13.9					
VPD2-10R5-3B		2	55.6	35	17.5	6	13.4	21	10	0.6~1.7		
VPD2-10R5-4B		2.5				7	14.9					
VPD2-10R5-6B		4				7	14.9					
VPD2-15R5-3B		2	66.6	40	23.5	6	13.4	26	15	0.4~1.7		
VPD2-15R5-4B		2.5				7	14.9					
VPD2-15R5-6B		4				7	14.9					
VPD2-20R5-3B		2	76.6	45	28.5	6	13.4	31	20	0.3~1.8		
VPD2-20R5-4B		2.5				7	14.9					
VPD2-20R5-6B		4				7	14.9					
VPD3-3R5-3B9	3	2	—	—	—	6	12.4	—	3	0.9~1.9		
VPD3-3R5-4B9		2.5				7	13.9				3	0.9~1.9
VPD3-3R5-6B9		4				7	13.9					
VPD3-10R5-3B		2	55.6	35	17.5	6	13.4	21	10	0.6~1.7		
VPD3-10R5-4B		2.5				7	14.9					
VPD3-10R5-6B		4				7	14.9					
VPD3-15R5-3B		2	66.6	40	23.5	6	13.4	26	15	0.4~1.7		
VPD3-15R5-4B		2.5				7	14.9					
VPD3-15R5-6B		4				7	14.9					
VPD3-20R5-3B		2	76.6	45	28.5	6	13.4	31	20	0.3~1.8		
VPD3-20R5-4B		2.5				7	14.9					
VPD3-20R5-6B		4				7	14.9					
VPD4-3R5-3B9	4	2	—	—	—	6	12.4	—	3	0.9~1.9		
VPD4-3R5-4B9		2.5				7	13.9				3	0.9~1.9
VPD4-3R5-6B9		4				7	13.9					
VPD4-10R5-3B		2	55.6	35	17.5	6	13.4	21	10	0.6~1.7		
VPD4-10R5-4B		2.5				7	14.9					
VPD4-10R5-6B		4				7	14.9					
VPD4-15R5-3B		2	66.6	40	23.5	6	13.4	26	15	0.4~1.7		
VPD4-15R5-4B		2.5				7	14.9					
VPD4-15R5-6B		4				7	14.9					
VPD4-20R5-3B		2	76.6	45	28.5	6	13.4	31	20	0.3~1.8		
VPD4-20R5-4B		2.5				7	14.9					
VPD4-20R5-6B		4				7	14.9					

RoHS指令

✕ 銅系不使用品も用意

CAD(2D&3D)