

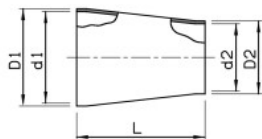
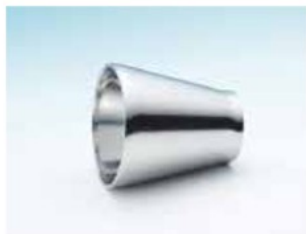


溶接継手

溶接用コンセントレジャーサー T-13

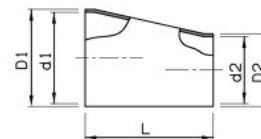

溶接用エキセントレジャーサー T-14

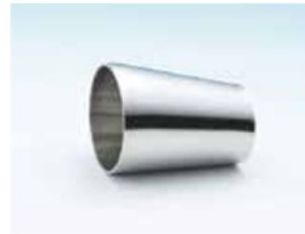

単位:mm

サイズ	D1	d1	D2	d2	L	T-13 重量 (kg)
10A× 8A	17.3	14.0	13.8	10.5	14.0	0.01
15A× 8A	21.7	18.4	13.8	10.5	24.0	0.02
15A×10A	21.7	18.4	17.3	14.0	19.0	0.01
1.0S× 8A	25.4	23.0	13.8	10.5	38.0	0.03
1.0S×10A	25.4	23.0	17.3	14.0	38.0	0.03
1.0S×15A	25.4	23.0	21.7	18.4	38.0	0.03
1.5S× 8A	38.1	35.7	13.8	10.5	38.0	0.03
1.5S×10A	38.1	35.7	17.3	14.0	38.0	0.04
1.5S×15A	38.1	35.7	21.7	18.4	38.0	0.05
1.5S×1.0S	38.1	35.7	25.4	23.0	67.0	0.07
2.0S×1.0S	50.8	47.8	25.4	23.0	67.0	0.10
2.0S×1.5S	50.8	47.8	38.1	35.7	67.0	0.11
2.5S×1.0S	63.5	59.5	25.4	23.0	67.0	0.13
2.5S×1.5S	63.5	59.5	38.1	35.7	67.0	0.18
2.5S×2.0S	63.5	59.5	50.8	47.8	67.0	0.20
3.0S×1.0S	76.3	72.3	25.4	23.0	67.0	0.16
3.0S×1.5S	76.3	72.3	38.1	35.7	67.0	0.23
3.0S×2.0S	76.3	72.3	50.8	47.8	67.0	0.24
3.0S×2.5S	76.3	72.3	63.5	59.5	67.0	0.24
3.5S×2.0S	89.1	85.1	50.8	47.8	90.0	0.27
3.5S×2.5S	89.1	85.1	63.5	59.5	90.0	0.34
3.5S×3.0S	89.1	85.1	76.3	72.3	90.0	0.35
4.0S×1.5S	101.6	97.6	38.1	35.7	102.0	0.35
4.0S×2.0S	101.6	97.6	50.8	47.8	120.0	0.45
4.0S×2.5S	101.6	97.6	63.5	59.5	120.0	0.51
4.0S×3.0S	101.6	97.6	76.3	72.3	102.0	0.48
4.0S×3.5S	101.6	97.6	89.1	85.1	120.0	0.55
4.5S×4.0S	114.3	108.3	101.6	97.6	130.0	0.86
5.0S×4.0S	139.8	133.8	101.6	97.6	160.0	1.27

※概算重量としてT-14はT-13を参考にして下さい。