
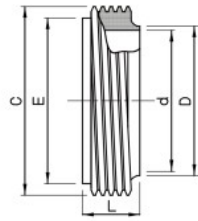


## ISO ネジ(ユニオン)継手



溶接用ネジスリーブ W-MALE

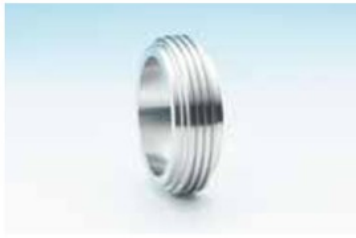

単位:mm

サイズ	D	d	C	E	L	重量(kg)
1.0S	25.4	23.0	36.9	29.2	20.5	0.07
1.5S	38.1	35.7	50.4	42.7	20.5	0.11
2.0S	50.8	47.8	64.0	56.2	20.5	0.16
2.5S	63.5	59.5	77.5	69.9	20.5	0.22
3.0S	76.3	72.3	91.0	82.6	20.5	0.27
4.0S	101.6	97.6	119.0	108.7	27.1	0.52


溶接用スリーブ W-LINER

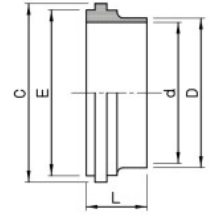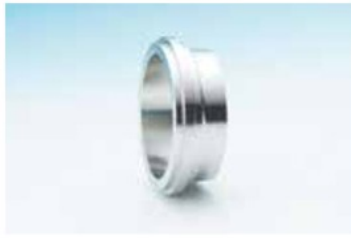

単位:mm

サイズ	D	d	C	E	L	重量(kg)
1.0S	25.4	23.0	33.8	29.2	20.5	0.04
1.5S	38.1	35.7	47.0	42.7	20.5	0.06
2.0S	50.8	47.8	60.5	56.2	20.5	0.09
2.5S	63.5	59.5	74.0	69.9	20.5	0.14
3.0S	76.3	72.3	87.5	82.6	20.5	0.17
4.0S	101.6	97.6	114.1	108.7	27.1	0.32



溶接用ネジスリーブ(ロング) LW-MALE

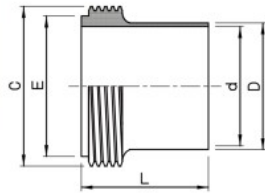

単位:mm

サイズ	D	d	C	E	L	重量(kg)
1.0S	25.4	23.0	36.9	29.2	51.0	0.09
1.5S	38.1	35.7	50.4	42.7	51.0	0.14
2.0S	50.8	47.8	64.0	56.2	51.0	0.21
2.5S	63.5	59.5	77.5	69.9	51.0	0.32
3.0S	76.3	72.3	91.0	82.6	51.0	0.39
4.0S	101.6	97.6	119.0	108.7	56.0	0.68


溶接用スリーブ(ロング) LW-LINER

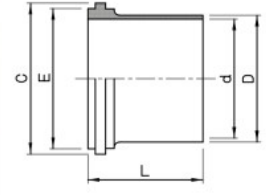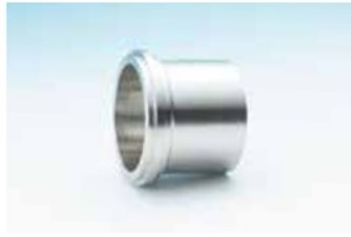

単位:mm

サイズ	D	d	C	E	L	重量(kg)
1.0S	25.4	23.0	33.8	29.2	46.0	0.06
1.5S	38.1	35.7	47.0	42.7	46.0	0.09
2.0S	50.8	47.8	60.5	56.2	46.0	0.13
2.5S	63.5	59.5	74.0	69.9	46.0	0.21
3.0S	76.3	72.3	87.5	82.6	46.0	0.26
4.0S	101.6	97.6	114.1	108.7	49.0	0.42



セードル用ネジスリーブ E-MALE

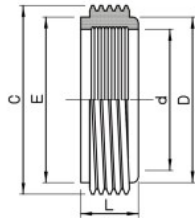

単位:mm

サイズ	D	d	C	E	L	重量(kg)
1.0S	29.5	25.6	36.9	29.0	17.0	0.05
1.5S	42.6	38.3	50.4	42.6	19.5	0.08
2.0S	56.0	51.0	64.0	56.0	19.5	0.12
2.5S	69.0	63.8	77.5	69.7	25.0	0.17
3.0S	82.0	76.6	91.0	82.3	30.0	0.24

セードル用スリーブ E-LINER

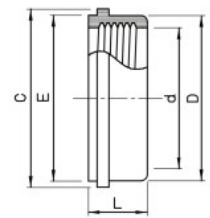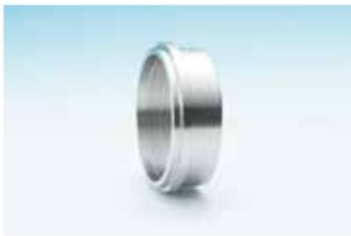

単位:mm

サイズ	D	d	C	E	L	重量(kg)
1.0S	29.5	25.6	33.5	29.0	17.0	0.02
1.5S	42.6	38.3	47.0	42.6	20.0	0.04
2.0S	56.0	51.0	60.5	56.0	20.0	0.07
2.5S	69.0	63.8	74.0	69.7	25.0	0.12
3.0S	82.0	76.6	87.5	82.3	30.0	0.16