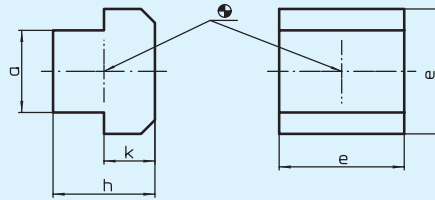


EH 23010.

T-ナット

DIN508
半製品

材質:

- 熱処理鋼、表面処理なし
- ステンレス鋼 1.4305 (SUS303相当)



製品番号 熱処理鋼	製品番号 ステンレス鋼	T溝幅	a	e	h	k	g
23010.0060	—	6	5.6	10	8	4	4
23010.0080	23010.0720	8	7.6	13	10	6	10
23010.0100	23010.0730	10	9.6	15	12	6	17
23010.0120	23010.0740	12	11.6	18	14	7	27
23010.0140	23010.0750	14	13.6	22	16	8	46
23010.0160	23010.0760	16*	15.6	25	18	9	68
23010.0180	23010.0780	18	17.6	28	20	10	95
23010.0200	—	20*	19.6	32	24	12	149
23010.0220	—	22	21.6	35	28	14	210
23010.0240	—	24*	23.6	40	32	16	300
23010.0280	—	28	27.6	44	36	18	430
23010.0320	—	32*	31.5	50	40	20	580
23010.0360	—	36	35.5	54	44	22	800
23010.0420	—	42	41.5	65	52	26	1250
23010.0480	—	48	47.5	75	60	30	1900
23010.0540	—	54	53.4	85	70	34	2600

* この寸法のはものはDIN規格にはありません。