

マシン・ハンドル・DIN 39

EH 24450.



製品説明

材質

- スティール、旋削加工、亜鉛メッキ、不活性化処理
- ステンレス鋼 1.4404 ( SUS316L相当 )

寸法図

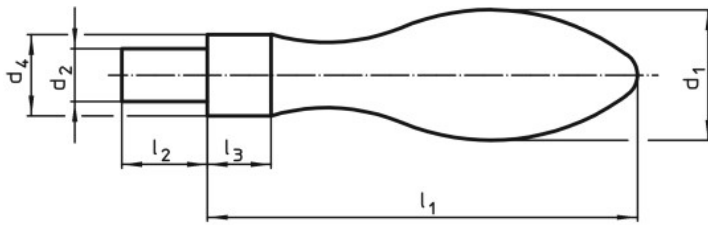


図 1

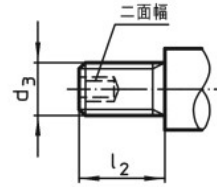


図 2

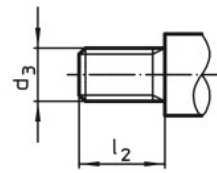


図 3

発注情報

d <sub>1</sub>	d <sub>2</sub> h8	d <sub>3</sub>	寸法				二面幅 [mm]	重量 [g]	製品番号	
			d <sub>4</sub> h13 [mm]	l <sub>1</sub> 約	l <sub>2</sub>	l <sub>3</sub>			鋼	ステンレス鋼
はめあい軸付 形状D - 図 1										
16	7	-	10	50	11	7	-	45	24450.0016	-
20	8	-	13	64	13	8	-	92	24450.0020	-
25	10	-	16	80	14	10	-	177	24450.0025	-
32	13	-	20	100	21	13	-	359	24450.0032	-
36	16	-	22	112	26	14	-	519	24450.0036	-
オネジ付 形状E - 図 2										
16	-	M 6	10	50	11	7	3	43	24450.0116	-
20	-	M 8	13	64	13	8	4	88	24450.0120	-
25	-	M10	16	80	14	10	5	175	24450.0125	-
32	-	M12	20	100	21	13	6	346	24450.0132	-
36	-	M16	22	112	26	14	8	509	24450.0136	-
オネジ付 形状E - 図 3										
16	-	M 6	10	50	11	7	-	45	-	24450.0316
20	-	M 8	13	64	13	8	-	92	-	24450.0320
25	-	M10	16	80	14	10	-	186	-	24450.0325

応用例

