



プラグ

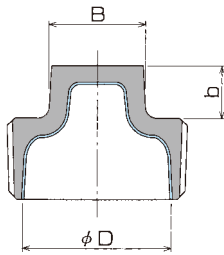

●P

呼び (B)	二面幅 B	b	D
1/2	14	10	15.5
3/4	17	11	21
1	19	12	26
1 1/4	23	13	35
1 1/2	26	14	41.5
2	32	15	52
2 1/2	41	18	66.5
3	46	19	79
4	58	22	103.5
5	67	25	128
6	77	28	152


クロスオーバー

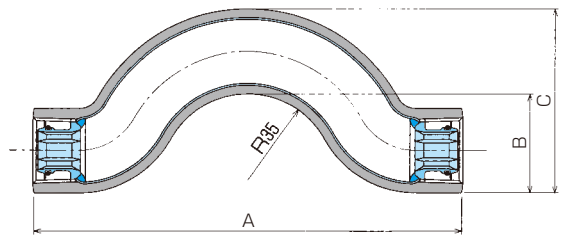

●OS

呼び	A	B	C
3/4	172	40	74

径違いエルボ

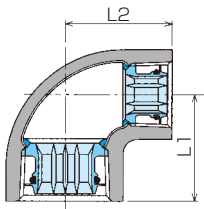


●RL

呼び	L1	L2
3/4 × 1/2	29	30
1 × 1/2	32	33
1 × 3/4	34	35
1 1/4 × 3/4	38	40
1 1/4 × 1	40	42
1 1/2 × 3/4	38	43
1 1/2 × 1	41	45
1 1/2 × 1 1/4	45	48
2 × 3/4	41	49
2 × 1	44	51
2 × 1 1/4	48	54

呼び	L1	L2
2 × 1 1/2	52	55
2 1/2 × 1	48	60
2 1/2 × 1 1/2	55	62
2 1/2 × 2	60	65
3 × 1 1/2	58	72
3 × 2	62	72
3 × 2 1/2	72	75
4 × 2	69	87
4 × 2 1/2	78	90
4 × 3	83	91

径違いチーズ

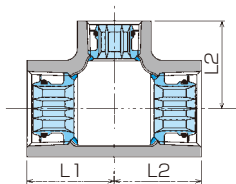


●RT

呼び	L1	L2
3/4 × 1/2	29	30
1 × 1/2	32	33
1 × 3/4	34	35
1 1/4 × 1/2	34	38
1 1/4 × 3/4	38	40
1 1/4 × 1	40	42
1 1/2 × 1/2	35	42
1 1/2 × 3/4	38	43
1 1/2 × 1	41	45
1 1/2 × 1 1/4	45	48
2 × 1/2	38	48
2 × 3/4	41	49
2 × 1	44	51
2 × 1 1/4	48	54

呼び	L1	L2
2 × 1 1/2	52	55
2 1/2 × 3/4	44	58
2 1/2 × 1	48	60
2 1/2 × 1 1/4	52	60
2 1/2 × 1 1/2	55	62
2 1/2 × 2	60	65
3 × 3/4	46	66
3 × 1	50	68
3 × 1 1/4	55	70
3 × 1 1/2	58	72
3 × 2	62	72
3 × 2 1/2	72	75
4 × 3/4	54	80
4 × 1	57	83

呼び	L1	L2
4 × 1 1/4	61	86
4 × 1 1/2	63	86
4 × 2	69	87
4 × 2 1/2	78	90
4 × 3	83	91
5 × 1 1/2	66	100
5 × 2	72	103
5 × 2 1/2	81	105
5 × 3	87	107
5 × 4	100	111
6 × 2 1/2	85	118
6 × 3	92	120
6 × 4	102	125
6 × 5	116	128

径違いソケット

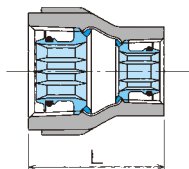

●RS

呼び	L
3/4 × 1/2	38
1 × 1/2	42
1 × 3/4	42
1 1/4 × 3/4	48
1 1/4 × 1	48
1 1/2 × 1/2	52
1 1/2 × 3/4	52
1 1/2 × 1	52
1 1/2 × 1 1/4	52
2 × 3/4	58
2 × 1	58
2 × 1 1/4	58
2 × 1 1/2	58
2 1/2 × 3/4	65
2 1/2 × 1	65

呼び	L
2 1/2 × 1 1/4	65
2 1/2 × 1 1/2	65
2 1/2 × 2	65
3 × 3/4	72
3 × 1	72
3 × 1 1/2	72
3 × 2	72
3 × 2 1/2	72
4 × 3/4	85
4 × 2	85
4 × 2 1/2	85
4 × 3	85
5 × 4	95
6 × 4	105
6 × 5	105