



寸法表

エルボ

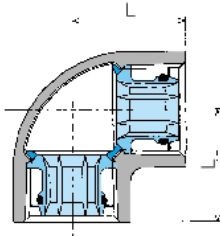


呼び	L
1/2	27
3/4	32
1	38
1 1/4	46
1 1/2	48
2	57
2 1/2	69
3	78
4	97
5	113
6	132

45°
エルボ

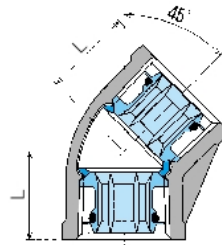


呼び	L
1/2	21
3/4	25
1	29
1 1/4	34
1 1/2	37
2	42
2 1/2	49
3	54
4	65
5	74
6	82

チーズ

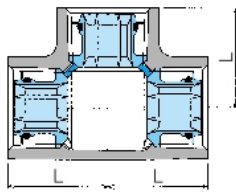


呼び	L
1/2	27
3/4	32
1	38
1 1/4	46
1 1/2	48
2	57
2 1/2	69
3	78
4	97
5	113
6	132

ソケット

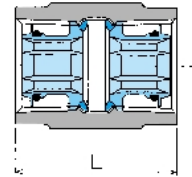

呼び	L
1/2	36
3/4	42
1	48
1 1/4	50
1 1/2	55
2	60
2 1/2	70
3	75
4	85
5	95
6	105

合フレンジ

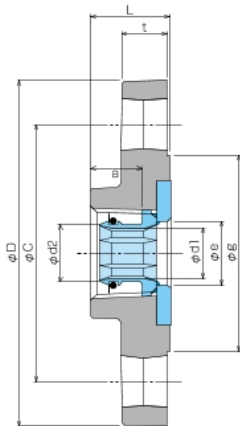


呼び (B)	C	D	t	L	e	g	d1	d2	a	使用ボルト		
										呼び	数	長さ
3/4	65	85	13	22	17	50	16	17.5	15	M10	4	45
1	75	95	13	25	23.5	61	20.5	22.5	17	M10	4	45
1 1/4	90	115	14	28	31	72	28.5	31	20	M12	4	50
1 1/2	95	120	14	28	37.5	77	33.5	36.5	20	M12	4	50
2	105	130	14	33	50	88	44.5	47.5	25	M12	4	50
2 1/2	130	155	16	37	65	112	59	63	28	M12	4	55
3	145	180	16	41	76	124	71	75	31	M16	4	60
4	165	200	18	47	100	141	95.5	99.5	37	M16	8	65

呼び (B)	C	D	t	L	e	g	d1	d2	a	使用ボルト		
										呼び	数	長さ
3/4	75	100	14	22	17	57	16	17.5	15	M12	4	50
1	90	125	15	25	23.5	68	20.5	22.5	17	M16	4	55
1 1/4	100	135	16	28	31	76	28.5	31	20	M16	4	60
1 1/2	105	140	16	28	37.5	81	33.5	36.5	20	M16	4	60
2	120	155	16	33	50	96	44.5	47.5	25	M16	4	60
2 1/2	140	175	18	37	65	116	59	63	28	M16	4	60
3	150	185	18	41	76	126	71	75	31	M16	8	60
4	175	210	18	47	100	151	95.5	99.5	37	M16	8	65
5	210	250	20	53	124.5	185	119	124	42	M20	8	70
6	240	280	22	53	147.5	212	142	147	42	M20	8	75

- (1) バタフライバルブと接続する場合は、開閉できることを確認してください。偏心型など特殊バタフライバルブには使用できない場合があります。
 (2) ボルト長さは参考値です。


ユニオン

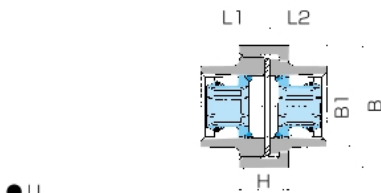

呼び (B)	L1	L2	H	二面幅 B	二面幅 B1
1/2	21.5	18.5	17.5	42	27
3/4	25.5	23	19	49	33
1	28	26	20.5	59	41
1 1/4	31	27	22.5	69	50
1 1/2	34	29.5	25	78	56
2	38	33.5	27.5	93	69
2 1/2	42	38.5	30	112	86

- (1) 専用ガスケットを出荷時に同梱します。(2) ガスケット材質はEPDMです。

ニップル

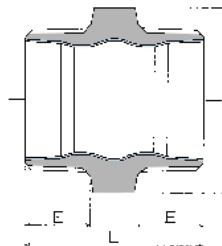

呼び	L	E	二面幅 B
1/2	43	16.5	26
3/4	47	18	32
1	51	19.5	38
1 1/4	54.5	21	46
1 1/2	59	22.5	54
2	65	24.5	63
2 1/2	74	29	80
3	81.5	32.5	95
4	92.5	37.5	120
5	103.5	41.5	145
6	114.5	45.5	170