


● LA 型・HI-LA マルチ・P-LA 型


ナット

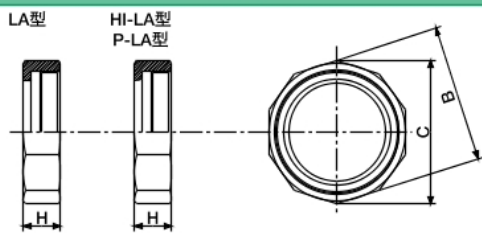

(mm)

呼び (鋼管)		B	H	C	角数
B	A	二面幅	高さ	対角寸法	
3/8	10	37	15	40	八角
1/2	15	42	17	46	八角
3/4	20	49	18	53	八角
1	25	58	18	63	八角
1 1/4	32	66	19	69	十角
1 1/2	40	73	22	77	十角
2	50	87	23	92	十角
2 1/2	65	108	29	114	十角
3	80	123	29	129	十角


ソケット (S)

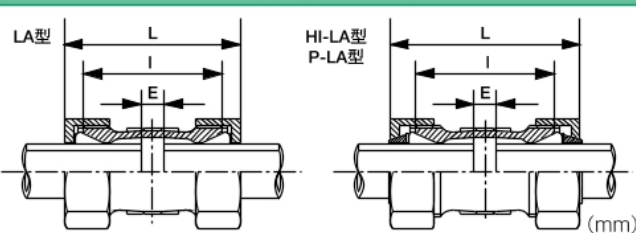

(mm)

呼び (鋼管)		LA 型			HI-LA マルチ・(P-LA 型)		
B	A	L	I	E	L	I	E
3/8	10	64	50	4	73 (73)	50	4
1/2	15	69	55	9	79 (78)	55	9
3/4	20	75	60	14	86 (84)	60	14
1	25	80	65	19	91 (89)	65	19
1 1/4	32	86	70	14	97 (95)	70	14
1 1/2	40	91	75	15	105 (101)	75	15
2	50	97	80	20	113 (108)	80	20
2 1/2	65	110	90	10	130 (126)	90	10
3	80	120	100	20	140 (136)	100	20


特寸ソケット (SSS)

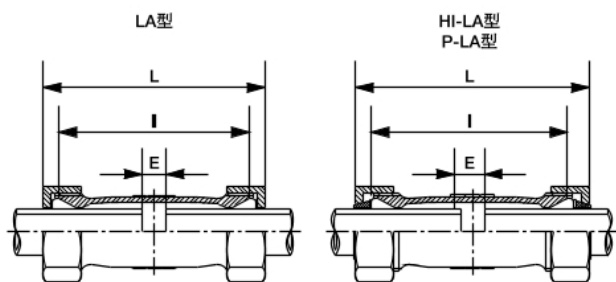

(mm)

呼び (鋼管)		LA 型			HI-LA マルチ・(P-LA 型)		
B	A	L	I	E	L	I	E
1/2	15	101	87	11	112 (111)	87	11
3/4	20	109	94	18	120 (118)	94	18
1	25	115	100	24	126 (124)	100	24
1 1/4	32	122	106	20	133 (131)	106	20
1 1/2	40	128	112	22	143 (139)	112	22
2	50	136	119	29	153 (147)	119	29


エルボ (L)

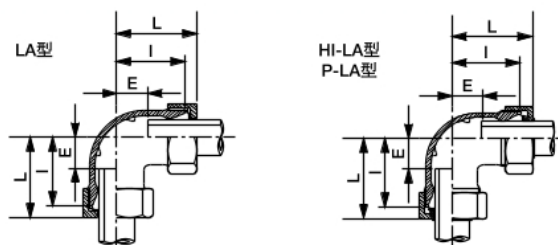

(mm)

呼び (鋼管)		LA 型			HI-LA マルチ・(P-LA 型)		
B	A	L	I	E	L	I	E
1/2	15	49	42	19	55 (54)	42	19
3/4	20	55	48	24	61 (60)	48	24
1	25	62	54	31	67 (66)	54	31
1 1/4	32	70	62	34	76 (75)	62	34
1 1/2	40	77	69	39	84 (82)	69	39
2	50	88	79	49	95 (93)	79	49
2 1/2	65	97	87	47	107 (105)	87	47
3	80	105	95	55	115 (113)	95	55


45° エルボ (45° L)

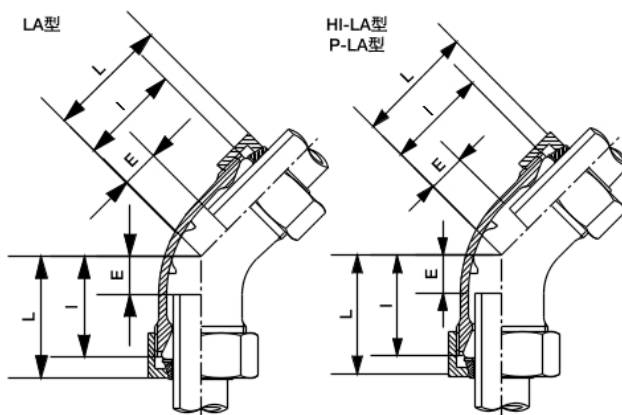

(mm)

呼び (鋼管)		LA 型			HI-LA マルチ・(P-LA 型)		
B	A	L	I	E	L	I	E
1 1/2	40	65	57	27	72 (70)	57	27
2	50	76	67	37	84 (81)	67	37

チーズ枝部ねじ付き (T)

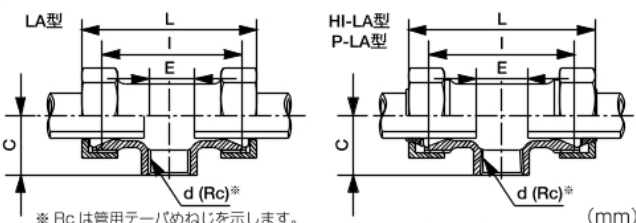

(mm)

* Rc は管用テーパねじを示します。

呼び (鋼管)		LA 型				HI-LA マルチ・(P-LA 型)			
B	A	L	I	C	E	L	I	C	E
1/2	15	85	71	29	25	95 (94)	71	29	25
3/4	20	97	82	34	36	108 (106)	82	34	36
1	25	106	91	40	45	117 (115)	91	40	45
1 1/4	32	122	106	46	50	133 (131)	106	46	50
1 1/2	40	133	117	51	57	147 (143)	117	51	57
2	50	150	133	59	73	166 (161)	133	59	73
2 1/2	65	178	158	71	78	198 (194)	158	71	78
3	80	191	171	81	91	211 (207)	171	81	91