

## 鉄 ⊕ ナベ小ねじ(半ねじ)(ねじ部100)



00001000

鉄

## M6.0

| 長さ  | 入り数    | 生地 | クロロ | クロメート | 三価ホワイト | 三価ブラック | ニッケル | 亜鉛黒 |
|-----|--------|----|-----|-------|--------|--------|------|-----|
| 105 | 150×10 | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 110 | 150×10 | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 115 | 130×10 | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 120 | 130×10 | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 125 | 120×10 | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 130 | 120×10 | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 135 | 150×8  | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 140 | 150×8  | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 145 | 150×8  | ●  | ●   | ●     | ●      | ●      | ●    | ●   |
| 150 | 150×8  | ●  | ●   | ●     | ●      | ●      | ●    | ●   |

## ⊕ ナベワッシャーヘッド小ねじ




0000000W

鉄

0002000W

ステンレス

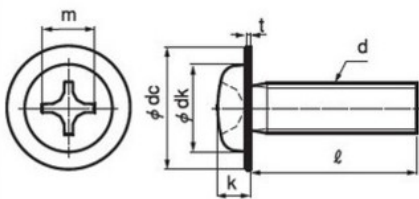

| 呼び径 | ピッチ | 十字穴の番号 | dk   |           | dc   |           | k    |      | t    |      | 十字穴 |      |      |
|-----|-----|--------|------|-----------|------|-----------|------|------|------|------|-----|------|------|
|     |     |        | 基準寸法 | 許容差       | 基準寸法 | 許容差       | 基準寸法 | 許容差  | 基準寸法 | 許容差  | m   | Q    |      |
|     |     |        |      |           |      |           |      |      |      |      | 参考  | 最大   | 最小   |
| M3  | 0.5 | 2      | 5.5  | 0<br>-0.5 | 8.0  | 0<br>-0.5 | 2.2  | ±0.2 | 0.5  | ±0.1 | 3.6 | 1.43 | 0.86 |
| M4  | 0.7 |        | 7.0  |           | 10.0 |           | 3.0  |      | 0.8  |      | 4.2 | 2.03 | 1.45 |
| M5  | 0.8 |        | 9.0  |           | 12.0 |           | 3.5  | ±0.3 | 1.0  | ±0.5 | 4.9 | 2.73 | 2.14 |
| M6  | 1.0 | 3      | 10.5 |           | 13.0 |           | 4.2  |      | 1.0  |      | 6.3 | 2.86 | 2.26 |

## M2.0

| 長さ | 入り数     | 鉄  |     |       |        |        |      |      |     |      |       |
|----|---------|----|-----|-------|--------|--------|------|------|-----|------|-------|
|    |         | 生地 | クロロ | クロメート | 三価ホワイト | 三価ブラック | ニッケル | クローム | 亜鉛黒 | 黒ツケル | ステンレス |
| 3  | 7000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 4  | 5000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 5  | 6000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 6  | 5000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 7  | 6000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 8  | 4000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 10 | 4000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 10 | 5000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 12 | 3000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 14 | 3000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 16 | 2500×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 18 | 2200×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 19 | 2000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |
| 20 | 1500×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |

## M2.6

| 長さ | 入り数     | 鉄  |     |       |        |        |      |      |     |      |       | ステンレス |
|----|---------|----|-----|-------|--------|--------|------|------|-----|------|-------|-------|
|    |         | 生地 | クロロ | クロメート | 三価ホワイト | 三価ブラック | ニッケル | クローム | 亜鉛黒 | 黒ツケル | ステンレス |       |
| 3  | 3500×24 |    |     |       |        |        |      |      |     |      |       | ●     |
| 4  | 3000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 4  | 3000×24 |    |     |       |        |        |      |      |     |      |       | ●     |
| 5  | 3000×20 |    | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 5  | 3000×24 |    |     |       |        |        |      |      |     |      |       | ●     |
| 6  | 2500×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 6  | 2500×24 |    |     |       |        |        |      |      |     |      |       | ●     |
| 8  | 2000×20 | ●  | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 8  | 2400×20 |    |     |       |        |        |      |      |     |      |       | ●     |
| 10 | 1800×20 |    | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 10 | 2000×24 |    |     |       |        |        |      |      |     |      |       | ●     |
| 12 | 1500×24 |    |     |       |        |        |      |      |     |      |       | ●     |
| 12 | 1600×20 |    | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 14 | 1500×20 |    | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 15 | 1300×20 |    | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |
| 16 | 1200×20 |    | ●   | ●     | ●      | ●      | ●    | ●    | ●   | ●    | ●     |       |