

⊕ 皿小ねじ(半ねじ)(ねじ部50)

M5.0											
長さ	入り数	鉄								ステンレス	
		生地	クロクロ	クロメイト	三層ホワイト	三層ブラック	ニッケル	クロム	亜鉛黒		パーカー
75	200×14	●	●	●	●	●	●	●	●	●	
80	200×14	●	●	●	●	●	●	●	●	●	
85	250×10	●	●	●	●	●	●	●	●	●	
90	250×10	●	●	●	●	●	●	●	●	●	
95	250×10	●	●	●	●	●	●	●	●	●	
100	250×10	●	●	●	●	●	●	●	●	●	
105	200×10	●	●	●	●	●	●	●	●	●	
110	200×10	●	●	●	●	●	●	●	●	●	
115	200×10	●	●	●	●	●	●	●	●	●	
120	200×10	●	●	●	●	●	●	●	●	●	
125	200×10	●	●	●	●	●	●	●	●	●	
130	200×10	●	●	●	●	●	●	●	●	●	
130	200×8	●	●	●	●	●	●	●	●	●	
135	200×8	●	●	●	●	●	●	●	●	●	
140	200×8	●	●	●	●	●	●	●	●	●	
150	200×8	●	●	●	●	●	●	●	●	●	
155	200×8	●	●	●	●	●	●	●	●	●	
160	200×8	●	●	●	●	●	●	●	●	●	
165	200×6	●	●	●	●	●	●	●	●	●	
170	200×6	●	●	●	●	●	●	●	●	●	
175	200×6	●	●	●	●	●	●	●	●	●	
180	200×6	●	●	●	●	●	●	●	●	●	
185	200×6	●	●	●	●	●	●	●	●	●	
190	200×6	●	●	●	●	●	●	●	●	●	
195	200×6	●	●	●	●	●	●	●	●	●	
210	200×6	●	●	●	●	●	●	●	●	●	
220	200×6	●	●	●	●	●	●	●	●	●	
240	200×4	●	●	●	●	●	●	●	●	●	
250	200×4	●	●	●	●	●	●	●	●	●	


M6.0											
長さ	入り数	鉄								ステンレス	
		クロクロ	クロメイト	三層ホワイト	ニッケル	亜鉛黒	クロム	パーカー	グリーン		
110	150×10	●	●	●	●	●	●	●	●	●	
120	100×10	●	●	●	●	●	●	●	●	●	
120	150×10	●	●	●	●	●	●	●	●	●	
130	100×10	●	●	●	●	●	●	●	●	●	
130	150×8	●	●	●	●	●	●	●	●	●	
140	150×8	●	●	●	●	●	●	●	●	●	
150	150×8	●	●	●	●	●	●	●	●	●	
160	150×8	●	●	●	●	●	●	●	●	●	
170	150×6	●	●	●	●	●	●	●	●	●	
180	150×6	●	●	●	●	●	●	●	●	●	
180	150×8	●	●	●	●	●	●	●	●	●	
190	150×6	●	●	●	●	●	●	●	●	●	
190	150×8	●	●	●	●	●	●	●	●	●	
200	150×6	●	●	●	●	●	●	●	●	●	
200	150×8	●	●	●	●	●	●	●	●	●	
210	150×6	●	●	●	●	●	●	●	●	●	
220	150×6	●	●	●	●	●	●	●	●	●	
230	150×4	●	●	●	●	●	●	●	●	●	
240	150×4	●	●	●	●	●	●	●	●	●	
250	150×4	●	●	●	●	●	●	●	●	●	

M8.0											
長さ	入り数	鉄								ステンレス	
		生地	クロクロ	クロメイト	三層ホワイト	ニッケル	亜鉛黒	ドブ	ニッケル		
105	80×10	●	●	●	●	●	●	●	●	●	
110	50×14	●	●	●	●	●	●	●	●	●	
110	80×10	●	●	●	●	●	●	●	●	●	
115	80×10	●	●	●	●	●	●	●	●	●	
120	50×14	●	●	●	●	●	●	●	●	●	
120	80×10	●	●	●	●	●	●	●	●	●	
125	80×10	●	●	●	●	●	●	●	●	●	
130	50×10	●	●	●	●	●	●	●	●	●	
130	80×10	●	●	●	●	●	●	●	●	●	
135	80×8	●	●	●	●	●	●	●	●	●	
140	80×8	●	●	●	●	●	●	●	●	●	
145	80×8	●	●	●	●	●	●	●	●	●	
150	80×8	●	●	●	●	●	●	●	●	●	

⊕ 皿小ねじ 小頭



- 00000006  
鉄
- 00010006  
黄銅
- 00020006  
ステンレス
- 00060006  
アルミ
- 00090006  
チタン

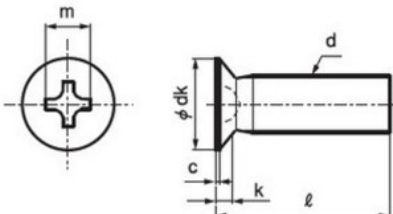

ねじの呼び	十字穴の番号	dk		K		C (約)	m (約)	q(十字穴深さ)	
		基準寸法	許容差	基準寸法	許容差			最大	最小
M3	1	5	0 -0.4	1.3	0 -0.2	0.20	2.6	1.42	1.05
M4	2	6	0	1.4	0 -0.3	0.25	3.6	1.43	0.91
M5		8	-0.5	1.9		0.30	4.5	2.33	1.79
M6	3	10	0 -0.6	2.4	0 -0.4	0.30	5.1	2.93	2.38
M8		12.0	0 0.7	2.6		0.40	6.7	3.26	2.70

M3.0												
長さ	入り数	鉄								ステンレス		
		生地	クロクロ	クロメイト	三層ホワイト	三層ブラック	ニッケル	クロム	亜鉛黒	パーカー	グリーン	生地
4	3000×24										●	●
4	4000×20	●	●	●	●	●	●	●	●	●	●	●
5	3000×24										●	●
5	4000×20	●	●	●	●	●	●	●	●	●	●	●
6	3000×24										●	●
6	3500×20	●	●	●	●	●	●	●	●	●	●	●
7	2000×24										●	●
8	2000×24										●	●
8	2500×20	●	●	●	●	●	●	●	●	●	●	●
10	2000×24										●	●
10	2200×20	●	●	●	●	●	●	●	●	●	●	●
12	2000×24										●	●
12	2500×14	●	●	●	●	●	●	●	●	●	●	●
14	2000×18										●	●
14	2500×14	●	●	●	●	●	●	●	●	●	●	●
15	1000×24										●	●
15	2000×14	●	●	●	●	●	●	●	●	●	●	●
16	1000×24										●	●
18	1000×24										●	●
20	1000×24										●	●
25	1200×14			●							●	●

小ねじ  
 マフクロねじ  
 組込みねじ  
 タツピンねじ  
 タツタイト  
 ハイエタねじ  
 いたすら防止ねじ  
 建材用スクリーン  
 ボルト  
 キャップ・ホーロー  
 ドリルねじ  
 座金  
 つまみねじ  
 ナット  
 樹脂製品  
 アンカーボルト