


ステンレス ⊕ トラス小ねじ 小頭



00020008

ステンレス

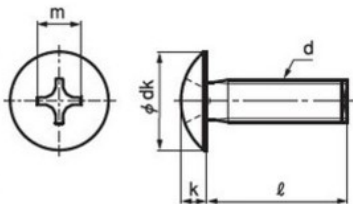

ねじの呼び (d)	ピッチ P	十字穴の 番号	dk		k		m	q(十字穴深さ)	
			基準寸法	許容差	基準寸法	許容差		最大	最小
M4	0.7	2	8.1	0 -0.5	2.2	±0.15	4.0	1.83	1.30
M5	0.8	2	10.6	0 -0.6	2.8	±0.15	4.7	2.53	1.99

M4.0										
長さ	入り数	生地	SC100	SC125	SC150	SC175	SC200	SC250	SC300	SC4
4	2000×18	●								
5	2000×18	●	●	●					●	●
6	2000×18	●	●	●	●	●	●	●	●	●
7	1000×24	●								
8	1000×24	●	●	●	●	●	●	●	●	●
10	1000×24	●	●	●	●	●	●	●	●	●
11	1000×18	●							●	
12	1000×18	●	●	●	●	●	●	●	●	●
14	1000×18	●	●	●	●	●	●	●	●	●
15	1000×18	●	●	●	●	●	●	●	●	●
16	1000×18	●	●	●	●	●	●	●	●	●
18	500×24	●								
20	500×24	●	●	●	●	●	●	●	●	●
25	500×18	●	●	●	●	●	●	●	●	●
28	500×18	●							●	●
30	500×18	●	●	●	●	●	●	●	●	●
35	200×24	●	●	●	●	●	●	●	●	●
40	200×24	●	●	●	●	●	●	●	●	●
45	200×18	●	●	●	●	●	●	●	●	●
50	200×18	●	●	●	●	●	●	●	●	●


M5.0										
長さ	入り数	生地	SC100	SC125	SC150	SC175	SC200	SC250	SC300	SC4
8	500×24	●	●	●	●	●	●	●	●	●
10	500×24	●	●	●	●	●	●	●	●	●
12	500×18	●	●	●	●	●	●	●	●	●
14	500×18	●	●	●	●	●	●	●	●	●
15	500×18	●	●	●	●	●	●	●	●	●
16	500×18	●	●	●	●	●	●	●	●	●
20	400×18	●	●	●	●	●	●	●	●	●
25	200×24	●	●	●	●	●	●	●	●	●
30	200×24	●	●	●	●	●	●	●	●	●
45	100×24	●								

ステンレス ⊕ トラス小ねじ D=8大頭



0002000G

ステンレス

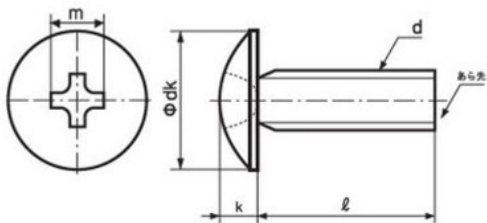

ねじの呼び (d)	ピッチ	十字穴の 番号	dk		K		m 参考
			基準寸法	許容差	基準寸法	許容差	
M3	0.5	2	8.1	-0.5	2.2	±0.15	4.0

M3.0		
長さ	入り数	生地
6	2000×10	●