

⊕ ⊖ バインド小ねじ



小ねじ

マフロねじ

組込みねじ

タツピンねじ

タツタイト・
ハイテックねじ

いたすら防止ねじ
建材用スクリュー

ボルト

キャップホーロー

ドリルねじ

座金

つまみねじ

ナット

樹脂製品

アンカーボルト

00000204


鉄

00010204

黄銅

00020204

ステンレス

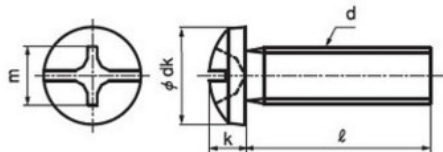

ねじの呼び (d)	ピッチ P	十字穴 の番号	dk		k+f		m	(十字穴深さ)		n (割幅)
			基準 寸法	許容差	基準 寸法	許容差		最大	最小	
M3	0.5	2	6.3	0 -0.5	1.9	±0.2	3.7	1.53	1.01	0.80
M3.5	0.6		7.3		2.2		4.0	1.83	1.30	1.00
M4	0.7		8.3		2.5		4.3	2.13	1.60	1.00
M5	0.8	3	10.3	0 -0.6	3.1	±0.3	5.0	2.83	2.29	1.20
M6	1.0		12.4	0 -0.7	3.7		6.3	2.86	2.31	1.20

M3.0

長さ	入り数	鉄										黄銅		ステンレス
		生地	クロメート	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	クロム	クロム	生地	ニッケル	
4	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
5	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
5	4000×14											●	●	
6	2000×24													●
6	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●
6	3500×14											●	●	
8	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×24													●
8	3000×14													●
10	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×18													●
12	2000×14											●	●	
12	2000×18													●
12	2200×14	●	●	●	●	●	●	●	●	●	●	●	●	●
14	2000×14											●	●	
16	1800×14	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1000×24													●
25	500×24													●

M3.5

長さ	入り数	鉄										黄銅	
		生地	クロメート	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	クロム	クロム	生地	ニッケル
6	2500×14	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×14	●	●	●	●	●	●	●	●	●	●	●	●

M4.0

長さ	入り数	鉄										黄銅		ステンレス
		生地	クロメート	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	クロム	クロム	生地	ニッケル	
5	1600×14													
5	1800×14	●	●	●	●	●	●	●	●	●	●	●	●	●
5	2000×14													●
6	1000×24													●
6	1500×14											●	●	
6	1600×14	●	●	●	●	●	●	●	●	●	●	●	●	●
8	1000×24													●
8	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×18													●
10	1200×14	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1500×14													●
12	1000×18													●
12	1200×14	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1500×14													●
14	900×14	●	●	●	●	●	●	●	●	●	●	●	●	●
15	1000×14													●
16	1000×14													●
16	900×14	●	●	●	●	●	●	●	●	●	●	●	●	●
18	500×24													●
20	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●
25	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●

M5.0

長さ	入り数	黄銅	
		生地	ニッケル
8	1000×14	●	●
12	800×14	●	●