

真鍮 ⊖ JIS丸小ねじ

00010115

黄銅

M3.0			M4.0			M5.0		
長さ	入り数	生地	長さ	入り数	生地	長さ	入り数	生地
5	3000×20	●	5	1500×20	●	6	800×20	●
6	3000×20	●	6	2500×10	●	8	700×20	●
8	2000×20	●	8	1000×15	●	10	700×20	●
10	2000×20	●	12	1000×20	●	12	500×20	●
12	1500×20	●	15	700×20	●	15	500×20	●
15	1000×20	●	16	1000×20	●	16	400×20	●
16	1000×20	●	20	500×20	●	20	400×20	●
20	1000×20	●	25	500×20	●	25	300×20	●
25	700×20	●	30	400×14	●	30	200×20	●
30	500×20	●						

⊖ 平小ねじ



0000010C


鉄

0001010C

黄銅

0002010C

ステンレス

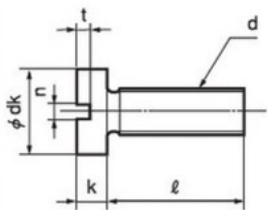

ねじの呼び (d)	ピッチ P	dk		k		n		t	
		基準寸法	許容差	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差
M3	0.5	5.5	0	2	±0.15	0.8	+0.15	1.1	±0.15
M4	0.7	7	-0.5	2.6		1	0	1.4	±0.2
M5	0.8	9	0 -0.6	3.3	±0.2	1.2	+0.2 0	1.8	±0.3
M6	1.0	10.5	0 -0.7	3.9		1.2		2.1	
M8	1.25	14	0 0.8	5.2	1.6	2.8	±0.5		

M1.0		
長さ	入り数	生地
2	1000×24	●
2.5	1000×24	●
3	1000×24	●
4	1000×24	●

M1.2		
長さ	入り数	生地
2	1000×24	●
2.5	1000×24	●
3	1000×24	●
4	1000×24	●

M1.4		
長さ	入り数	生地
2	1000×24	●
2.5	1000×24	●
3	1000×24	●
4	1000×24	●

M1.6		
長さ	入り数	生地
2	1000×24	●
3	1000×24	●
4	1000×24	●

M2.0		鉄					ステンレス
長さ	入り数	生地	コクロ	クロメイト	三価ホワイト	ニッケル	インコボンド
		3	5000×20				
4	5000×20						●
4	8000×20	●	●	●	●	●	●
5	5000×20						●
5	7000×20	●	●	●	●	●	●
6	4000×20	●	●	●	●	●	●
8	4000×20						●
8	5000×20	●	●	●	●	●	●
10	3500×20						●
10	4000×20	●	●	●	●	●	●