


⊕ アプセット小ねじ(六角頭)



0000000A 鉄	0001000A 黄銅	0002000A ステンレス
---------------	----------------	-------------------

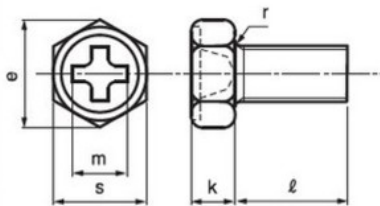

ねじの呼び	十字穴の番号	s		e	k		m	q		r
		基準寸法	許容差	参考	基準寸法	許容差	参考	最大	最小	最小
M3	2	5.5	0 -0.2	6.05	2.0	±0.1	3.5	1.43	0.91	0.1
M3.5		6.0		6.6	2.4		3.5	1.43	0.91	0.1
M4		7.0		7.7	2.8		4.0	1.93	1.40	0.2
M5		8.0		8.7	3.5		4.8	2.73	2.19	0.2
M6	3	10.0	0 -0.25	10.9	4.0	±0.15	6.2	2.86	2.30	0.25
M8		13.0		14.1	5.5		7.2	3.86	3.20	0.4
M10		17.0		18.9	7.0		9.25	4.95	4.15	0.4

長さ	入り数	M3.0											
		鉄										ステンレス	
		生地	クロメイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	クロムメイト	クロムS	クロムP	クロムN	ステンレス
5	2000×24												●
5	2500×20	●	●	●	●	●	●	●	●	●	●	●	●
6	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
6	2000×24												●
8	1800×20	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×24												●
10	1500×20	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×18												●
12	2000×14	●	●	●	●	●	●	●	●	●	●	●	●
12	2000×18												●
15	1000×24												●
15	1800×14			●				●		●	●		●
20	1500×14	●		●									●

長さ	入り数	M4.0																		
		鉄										黄銅		ステンレス						
		生地	クロメイト	三価ホワイト	三価ブラック	ニッケル	クロム	亜鉛黒	クロムメイト	クロムS	クロムP	クロムN	生地	三価ブラック	ニッケル	生地	G (A2-70)	B (A2-70)	SC304	SC4
5	2000×14	●	●	●	●	●	●	●	●	●	●	●								
6	1000×24																			
6	1800×14	●	●	●	●	●	●	●	●	●	●	●								
6	2000×14														●					
8	1000×24																			
8	1600×14	●	●	●	●	●	●	●	●	●	●	●								
8	2000×14												●	●	●					
10	1000×18																			
10	1300×14	●	●	●	●	●	●	●	●	●	●	●								
10	1500×14														●					
12	1000×18																			
12	1200×14	●	●	●	●	●	●	●	●	●	●	●								
12	1500×14														●					
14	1000×14	●	●	●	●	●	●	●	●	●	●	●								
15	1000×14	●	●	●	●	●	●	●	●	●	●	●								
15	500×24																			
16	1000×14	●	●	●	●	●	●	●	●	●	●	●								
16	500×24																			
18	500×24																			
18	800×14	●	●	●	●	●	●	●	●	●	●	●								
20	500×24																			
20	800×14	●	●	●	●	●	●	●	●	●	●	●								
22	600×14	●	●	●	●	●	●	●	●	●	●	●								
25	500×18																			
25	600×14	●	●	●	●	●	●	●	●	●	●	●								
30	500×14	●	●	●	●	●	●	●	●	●	●	●								
30	500×18																			
35	200×24																			
35	400×14	●	●	●	●	●	●	●	●	●	●	●								
40	200×24																			
40	500×10	●	●	●	●	●	●	●	●	●	●	●								
45	500×10	●	●	●	●	●	●	●	●	●	●	●								
50	500×10	●	●	●	●	●	●	●	●	●	●	●								
55	400×10	●	●	●	●	●	●	●	●	●	●	●								