

鉄 ⊕ 取っ手用小ねじ




0000000N

鉄

特長

- めねじを切った取っ手を流し台等に裏側から締め付けて取り付ける為のネジです。
- 締め付け後出来るだけ出っ張らないよう頭部を薄くしてあります。
- 相手材がさほど硬くない木材の場合、首下のテーパ部は座ぐりなしでも相手材にめり込みます。

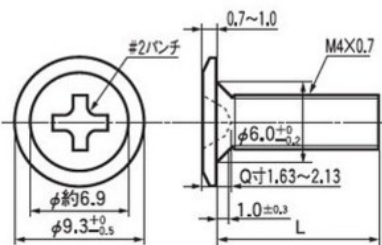

M4.0						
長さ	入り数	クロメート	三価ホウ素コート	INCOLOY	チタン	ステンレス
20	500×14	●	●	●	●	●
23	500×14	●	●	●	●	●
25	500×14	●	●	●	●	●
30	400×14	●	●	●	●	●
35	400×14	●	●	●	●	●
40	500×10	●	●	●	●	●
45	500×10	●	●	●	●	●

⊕ UNC(PAN) ユニファイ小ねじ




00000030

鉄

00020030

ステンレス

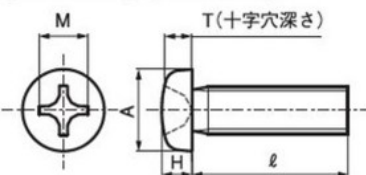

ねじの呼び	ねじ外径 参考	ピッチ	A(頭径)		H(頭高)		十字穴 番号
			最大	最小	最大	最小	
#1-64山	1.8	0.3969	3.606	3.302	1.346	1.117	0
#2-56山	2.1	0.4536	4.241	3.937	1.574	1.346	1
#3-48山	2.5	0.6350	4.902	4.572	1.803	1.574	1
#4-40山	2.8	0.6350	5.562	5.207	2.032	1.778	1
#6-32山	3.5	0.7938	6.858	6.5020	2.463	2.209	2
#8-32山	4.1	0.7938	8.178	7.772	2.921	2.667	2
#10-24山	4.8	1.0583	9.474	9.067	3.378	3.098	2
1/4-20山	6.3	1.27	12.496	12.014	4.445	4.114	3
5/16-18山	7.9	1.4111	15.621	15.087	5.537	5.156	4
3/8-16山	9.5	1.5875	18.796	18.186	6.629	6.197	4

#1		
長さ	入り数	ステンレス
1/4	100×1	●
3/8	100×1	●
1/2	100×1	●
3/4	100×1	●

#2		
長さ	入り数	ステンレス
1/8	100×1	●
5/32	5000×20	●
3/16	5000×20	●
1/4	5000×20	●
5/16	2000×20	●
5/16	5000×20	●
3/8	2000×20	●
7/16	100×1	●
1/2	2000×20	●
9/16	100×1	●
5/8	2000×20	●
3/4	1000×20	●
7/8	100×1	●
1"	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●

#3		
長さ	入り数	ステンレス
1/8	100×1	●
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●

#4		鉄										ステンレス	
長さ	入り数	生地	クロメート	三価ホウ素コート	三価ホウ素コート	チタン	チタン	チタン	チタン	チタン	チタン	チタン	チタン
		1/8	100×1	●	●	●	●	●	●	●	●	●	●
5/32	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
3/16	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
1/4	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
5/16	2000×20	●	●	●	●	●	●	●	●	●	●	●	●
3/8	1000×20	●	●	●	●	●	●	●	●	●	●	●	●
7/16	100×1	●	●	●	●	●	●	●	●	●	●	●	●
1/2	1000×20	●	●	●	●	●	●	●	●	●	●	●	●
9/16	100×1	●	●	●	●	●	●	●	●	●	●	●	●
5/8	1000×20	●	●	●	●	●	●	●	●	●	●	●	●
3/4	100×1	●	●	●	●	●	●	●	●	●	●	●	●
7/8	100×1	●	●	●	●	●	●	●	●	●	●	●	●
1"	100×1	●	●	●	●	●	●	●	●	●	●	●	●
1"1/8	100×1	●	●	●	●	●	●	●	●	●	●	●	●
1"1/4	100×1	●	●	●	●	●	●	●	●	●	●	●	●
1"3/8	100×1	●	●	●	●	●	●	●	●	●	●	●	●
1"1/2	100×1	●	●	●	●	●	●	●	●	●	●	●	●
1"3/4	100×1	●	●	●	●	●	●	●	●	●	●	●	●
2"	100×1	●	●	●	●	●	●	●	●	●	●	●	●
2"1/2	100×1	●	●	●	●	●	●	●	●	●	●	●	●
3"	100×1	●	●	●	●	●	●	●	●	●	●	●	●

#5		
長さ	入り数	ステンレス
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●