

#6		鉄										ステンレス	
長さ	入り数	生地	クロメート	クロムメット	三層クロムメット	ニッケル	亜鉛メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	●
		1/8	100×1										
5/32	1000×20	●	●	●	●	●	●	●	●	●	●	●	
3/16	1000×20	●	●	●	●	●	●	●	●	●	●	●	
1/4	1000×20	●	●	●	●	●	●	●	●	●	●	●	
5/16	1000×20	●	●	●	●	●	●	●	●	●	●	●	
3/8	1000×20	●	●	●	●	●	●	●	●	●	●	●	
7/16	100×1											●	
1/2	1000×20	●	●	●	●	●	●	●	●	●	●	●	
9/16	100×1											●	
5/8	500×20	●	●	●	●	●	●	●	●	●	●	●	
3/4	500×20	●	●	●	●	●	●	●	●	●	●	●	
7/8	100×1											●	
1"	500×20											●	
1"1/8	100×1											●	
1"1/4	500×20											●	
1"3/8	100×1											●	
1"1/2	200×20											●	
1"3/4	100×1											●	
2"	100×1											●	
2"1/4	100×1											●	
2"1/2	100×1											●	
3"	100×1											●	

#8		鉄										ステンレス	
長さ	入り数	生地	クロメート	クロムメット	三層クロムメット	ニッケル	亜鉛メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	●
		3/16	100×1										
1/4	1000×20	●	●	●	●	●	●	●	●	●	●	●	
5/16	1000×20	●	●	●	●	●	●	●	●	●	●	●	
3/8	500×20	●	●	●	●	●	●	●	●	●	●	●	
7/16	100×1											●	
1/2	500×20	●	●	●	●	●	●	●	●	●	●	●	
9/16	100×1											●	
5/8	500×20	●	●	●	●	●	●	●	●	●	●	●	
3/4	500×20	●	●	●	●	●	●	●	●	●	●	●	
7/8	100×1											●	
1"	400×20	●	●	●	●	●	●	●	●	●	●	●	
1"1/8	100×1											●	
1"1/4	200×20											●	
1"3/8	100×1											●	
1"1/2	200×20											●	
1"3/4	100×1											●	
2"	100×20											●	
2"1/4	100×1											●	
2"1/2	100×1											●	
2"3/4	100×1											●	
3"	100×1											●	
3-1/2	100×1											●	

#10		ステンレス
長さ	入り数	●
1/4	500×20	●
5/16	500×20	●
3/8	500×20	●
7/16	100×1	●
1/2	400×20	●
5/8	300×20	●
3/4	300×20	●
7/8	100×1	●
1"	200×20	●
1"1/8	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●
1"3/4	100×1	●
2"	100×20	●
2"1/4	100×1	●
2"1/2	100×1	●
3"	100×1	●
3"1/4	100×1	●
3-1/2	100×1	●

#12		ステンレス
長さ	入り数	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●
1"1/2	100×1	●

1/4		ステンレス
長さ	入り数	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
7/16	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
7/8	100×1	●
1"	100×1	●
1"1/8	100×1	●
1"1/4	100×1	●
1"3/8	100×1	●
1"1/2	100×1	●
1"3/4	100×1	●
2"	100×1	●
2"1/4	100×1	●
2"1/2	100×1	●
2"3/4	100×1	●
3"	100×1	●
3-1/2	100×1	●
4"	100×1	●


5/16		ステンレス
長さ	入り数	●
1/2	50×1	●
5/8	50×1	●
3/4	50×1	●
1"	50×1	●
1"1/4	50×1	●
1"1/2	50×1	●
1"3/4	50×1	●
2"	50×1	●
2"1/4	50×1	●
2"1/2	50×1	●
3"	50×1	●

3/8		ステンレス
長さ	入り数	●
5/8	50×1	●
3/4	50×1	●
1"	50×1	●
1"1/4	50×1	●
1"1/2	50×1	●
1"3/4	50×1	●
2"	50×1	●
2"1/2	50×1	●

⊕ UNF(PAN)ユニファイ小ねじ



00000040 鉄
00020040 ステンレス

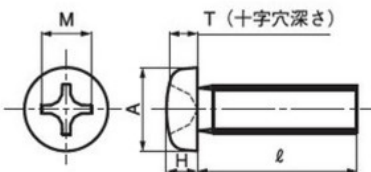

ねじの呼び	ねじ外径 参考	ピッチ	A(頭径)		H(頭高)		十字穴 番号
			最大	最小	最大	最小	
#0-80山	1.5	0.3175	2.946	2.641	1.117	0.914	0
#1-72山	1.8	0.3528	3.606	3.302	1.346	1.117	0
#2-64山	2.1	0.3969	4.241	3.937	1.574	1.346	1
#3-56山	2.5	0.4536	4.902	4.572	1.803	1.574	1
#4-48山	2.8	0.5292	5.562	5.207	2.032	1.778	1
#6-40山	3.5	0.6350	6.858	6.5020	2.463	2.209	2
#8-36山	4.1	0.7056	8.178	7.772	2.921	2.667	2
#10-32山	4.8	0.7938	9.474	9.067	3.378	3.098	2
1/4-28山	6.3	0.9071	12.496	12.014	4.445	4.114	3
5/16-24山	7.9	1.0583	15.621	15.087	5.537	5.156	4
3/8-24山	9.5	1.0583	18.796	18.186	6.629	6.197	4

小ねじ
メソクロねじ
組込みねじ
タッピンねじ
タツタイト
ハイエタねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップ・ホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト