

⊕ UNF(PAN)ユニファイ小ねじ

#0		
長さ	入り数	ステンレス
3/32	100×1	●
1/8	100×1	●
5/32	100×1	●
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●

#1		
長さ	入り数	ステンレス
1/8	100×1	●
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
1"	100×1	●

#2		
長さ	入り数	ステンレス
3/16	100×1	●
1/4	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●

#3		
長さ	入り数	ステンレス
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●

#4		
長さ	入り数	ステンレス
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●

#6		
長さ	入り数	ステンレス
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●

#8		
長さ	入り数	ステンレス
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●

#10			鉄								ステンレス		
長さ	入り数	生地	コクロ	クロメート	三層ホワイト	三層ブラック	亜鉛メッキ	メッキ	メッキ	メッキ	メッキ	生地	ステンレス
			生地	生地	生地	生地	生地	生地	生地	生地	生地	生地	生地
3/16	100×1											●	●
1/4	500×20		●	●	●	●	●	●	●	●	●	●	●
5/16	500×20		●	●	●	●	●	●	●	●	●	●	●
3/8	500×20		●	●	●	●	●	●	●	●	●	●	●
7/16	100×1											●	●
1/2	400×20		●	●	●	●	●	●	●	●	●	●	●
5/8	300×20		●	●	●	●	●	●	●	●	●	●	●
3/4	300×20		●	●	●	●	●	●	●	●	●	●	●
7/8	100×1											●	●
1"	200×20		●	●	●	●	●	●	●	●	●	●	●
1"1/8	100×1											●	●
1"1/4	200×20											●	●
1"3/8	100×1											●	●
1"1/2	100×20											●	●
1"3/4	100×1											●	●
2"	100×20											●	●
2"1/4	100×1											●	●
2"1/2	100×1											●	●
3"	100×1											●	●


1/4		
長さ	入り数	ステンレス
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●

ステンレス ⊕ UNC(FLAT)ユニファイ小ねじ



00020031

ステンレス

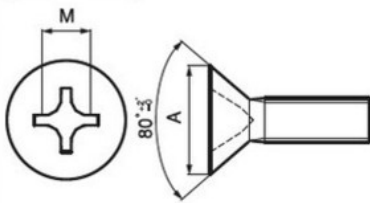

ねじの呼び	ねじ外径 参考	ピッチ	A(頭径)		H(頭高) 参考	十字穴 番号
			最大	最小		
#1-64山	1.8	0.3969	3.708	3.124	1.1	0
#2-56山	2.1	0.4536	4.368	3.733	1.3	1
#3-48山	2.5	0.6350	5.054	4.343	1.5	1
#4-40山	2.8	0.6350	5.715	4.953	1.7	1
#6-32山	3.5	0.7938	7.086	6.197	2.1	2
#8-32山	4.1	0.7938	8.432	7.416	2.5	2
#10-24山	4.8	1.0583	9.779	8.636	2.9	2
1/4-20山	6.3	1.27	12.877	11.48	3.9	3
5/16-18山	7.9	1.4111	16.129	14.427	4.8	4
3/8-16山	9.5	1.5875	19.354	17.399	5.8	4