

#2		
長さ	入り数	生地
1/8	100×1	●
3/16	100×1	●
1/4	5000×20	●
5/16	5000×20	●
3/8	2000×20	●
7/16	100×1	●
1/2	2000×20	●
5/8	2000×20	●
3/4	1000×20	●
7/8	100×1	●
1"	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●

#3		
長さ	入り数	生地
1/8	100×1	●
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●

#4		
長さ	入り数	生地
1/8	100×1	●
3/16	100×1	●
1/4	2000×20	●
5/16	2000×20	●
3/8	1000×20	●
7/16	100×1	●
1/2	1000×20	●
5/8	1000×20	●
3/4	100×1	●
7/8	100×1	●
1"	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●
1"3/4	100×1	●
2"	100×1	●

#5		
長さ	入り数	生地
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
1/2	100×1	●
3/4	100×1	●
1"	100×1	●

#6		
長さ	入り数	生地
3/16	100×1	●
1/4	1000×18	●
5/16	100×1	●
3/8	1000×20	●
7/16	100×1	●
1/2	1000×20	●
5/8	500×20	●
3/4	500×20	●
7/8	100×1	●
1"	500×20	●
1"1/8	100×1	●
1"1/4	500×20	●
1"1/2	200×20	●
1"3/4	100×1	●
2"	100×1	●
2"1/2	100×1	●
3"	100×1	●

#8		
長さ	入り数	生地
3/16	100×1	●
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
7/16	100×1	●
1/2	500×20	●
5/8	500×20	●
3/4	500×20	●
7/8	100×1	●
1"	500×20	●
1"1/8	100×1	●
1"1/4	200×20	●
1"1/2	200×20	●
1"3/4	100×1	●
2"	100×20	●
2"1/2	100×1	●
2"3/4	100×1	●
3"	100×1	●
3-1/2	100×1	●

#10		
長さ	入り数	生地
1/4	100×1	●
5/16	100×1	●
3/8	100×1	●
7/16	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
7/8	100×1	●
1"	100×1	●
1"1/8	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●
1"3/4	100×1	●
2"	100×1	●
2"1/2	100×1	●
3"	100×1	●
3-1/2	100×1	●
4"	100×1	●

#12		
長さ	入り数	生地
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
1"	100×1	●
1"1/2	100×1	●
2"	100×1	●

1/4		
長さ	入り数	生地
3/8	100×1	●
1/2	100×1	●
5/8	100×1	●
3/4	100×1	●
7/8	100×1	●
1"	100×1	●
1"1/4	100×1	●
1"1/2	100×1	●
1"3/4	100×1	●
2"	50×2	●
2"1/4	100×1	●
2"1/2	100×1	●
3"	100×1	●
3-1/2	100×1	●
4"	100×1	●

5/16		
長さ	入り数	生地
1/2	50×1	●
5/8	50×1	●
3/4	50×1	●
7/8	50×1	●
1"	50×1	●
1"1/4	50×1	●
1"1/2	50×1	●
1"3/4	50×1	●
2"	100×1	●
2"1/4	50×1	●
2"1/2	50×1	●
3"	50×1	●
3-1/2	50×1	●
4"	50×1	●


3/8		
長さ	入り数	生地
1/2	50×1	●
5/8	50×1	●
3/4	50×1	●
1"	50×1	●
1"1/4	50×1	●
1"1/2	50×1	●
1"3/4	50×1	●
2"	50×1	●
2"1/2	50×1	●
3"	50×1	●
3-1/2	50×1	●
4"	50×1	●

ステンレス ⊕ UNF(FLAT)ユニファイ小ねじ



00020041

ステンレス

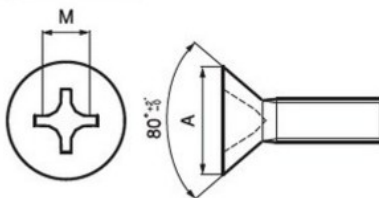

ねじの呼び	ねじ外径 参考	ピッチ	A(頭径)		H (頭高) 参考	十字穴 番号
			最大	最小		
#0—80山	1.5	0.3175	3.022	2.514	0.8	0
#1—72山	1.8	0.3528	3.708	3.124	1.1	0
#2—64山	2.1	0.3969	4.368	3.733	1.3	1
#3—56山	2.5	0.4536	5.054	4.343	1.5	1
#4—48山	2.8	0.5292	5.715	4.953	1.7	1
#6—40山	3.5	0.6350	7.086	6.197	2.1	2
#8—36山	4.1	0.7056	8.432	7.416	2.5	2
#10—32山	4.8	0.7971	9.779	8.636	2.9	2
1/4—28山	6.3	0.9071	12.877	11.48	3.9	3
5/16—24山	7.9	1.0583	16.129	14.427	4.8	4
3/8—24山	9.5	1.0583	19.354	17.399	5.8	4