

| #0              | #1              | #4              | #5              | #6              | #8              |
|-----------------|-----------------|-----------------|-----------------|-----------------|-----------------|
| 長さ<br>入り数<br>生地 | 長さ<br>入り数<br>生地 | 長さ<br>入り数<br>生地 | 長さ<br>入り数<br>生地 | 長さ<br>入り数<br>生地 | 長さ<br>入り数<br>生地 |
| 1/8 100×1 ●     | 1/8 100×1 ●     | 1/4 100×1 ●     | 1/4 100×1 ●     | 1/4 100×1 ●     | 3/8 100×1 ●     |
| 3/16 100×1 ●    | 3/16 100×1 ●    | 3/8 100×1 ●     | 3/8 100×1 ●     | 5/16 100×1 ●    | 5/16 100×1 ●    |
| 1/4 100×1 ●     | 1/4 100×1 ●     | 1/2 100×1 ●     |                 | 3/8 100×1 ●     | 3/8 100×1 ●     |
| 5/16 100×1 ●    | 5/16 100×1 ●    |                 |                 | 1/2 100×1 ●     |                 |
| 3/8 100×1 ●     | 3/8 100×1 ●     |                 |                 |                 |                 |
| 1/2 100×1 ●     | 1/2 100×1 ●     |                 |                 |                 |                 |
| 5/8 100×1 ●     | 1" 100×1 ●      |                 |                 |                 |                 |
| 3/4 100×1 ●     |                 |                 |                 |                 |                 |
| 1" 100×1 ●      |                 |                 |                 |                 |                 |


  

| #10             | 1/4             |
|-----------------|-----------------|
| 長さ<br>入り数<br>生地 | 長さ<br>入り数<br>生地 |
| 1/4 100×1 ●     | 3/8 100×1 ●     |
| 5/16 100×1 ●    | 1/2 100×1 ●     |
| 3/8 100×1 ●     | 5/8 100×1 ●     |
| 7/16 100×1 ●    | 3/4 100×1 ●     |
| 1/2 100×1 ●     | 1" 100×1 ●      |
| 5/8 300×20 ●    | 1"1/4 100×1 ●   |
| 3/4 300×20 ●    | 1"1/2 100×1 ●   |
| 7/8 100×1 ●     | 2" 100×1 ●      |
| 1" 200×20 ●     |                 |
| 1"1/8 100×1 ●   |                 |
| 1"1/4 200×20 ●  |                 |
| 1"1/2 100×20 ●  |                 |
| 1"3/4 100×1 ●   |                 |
| 2" 100×20 ●     |                 |
| 2"1/4 100×1 ●   |                 |
| 2"1/2 100×1 ●   |                 |
| 3" 100×1 ●      |                 |

## ⊕ スリムヘッド小ねじ



|          |          |
|----------|----------|
| 0000A300 | 0002A300 |
| 鉄        | ステンレス    |

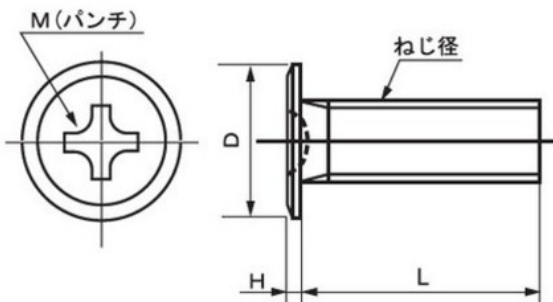

| ねじの呼び | D    |           | H    |      | 十字穴の番号 |
|-------|------|-----------|------|------|--------|
|       | 基準寸法 | 許容差       | 基準寸法 | 許容差  |        |
| M2    | 4.0  | 0<br>-0.5 | 0.5  | ±0.1 | 0      |
| M2.6  | 5.0  |           | 0.6  |      | 1      |
| M3    | 6.0  |           | 0.8  |      | 1      |
| M4    | 8.0  |           | 0.9  |      | 2      |
| M5    | 9.0  |           | 1.0  |      | 2      |
| M6    | 10.0 |           | 1.2  |      | 2      |

| M2.0                    | M2.6                    | M3.0                    | M4.0                    |
|-------------------------|-------------------------|-------------------------|-------------------------|
| 長さ<br>入り数<br>鉄<br>ステンレス | 長さ<br>入り数<br>鉄<br>ステンレス | 長さ<br>入り数<br>鉄<br>ステンレス | 長さ<br>入り数<br>鉄<br>ステンレス |
| 4 2000×20 ● ● ● ●       | 4 2000×20 ● ● ● ●       | 4 2000×20 ● ● ● ●       | 4 1000×20 ● ● ● ●       |
| 5 2000×20 ● ● ● ●       | 5 2000×20 ● ● ● ●       | 5 2000×20 ● ● ● ●       | 5 1000×20 ● ● ● ●       |
| 6 2000×20 ● ● ● ●       | 6 2000×20 ● ● ● ●       | 6 2000×20 ● ● ● ●       | 6 1000×20 ● ● ● ●       |
| 8 2000×20 ● ● ● ●       | 8 2000×20 ● ● ● ●       | 8 2000×20 ● ● ● ●       | 8 1000×20 ● ● ● ●       |
| 10 2000×20 ● ● ● ●      | 10 2000×20 ● ● ● ●      | 10 2000×20 ● ● ● ●      | 10 1000×20 ● ● ● ●      |
| 12 2000×20 ● ● ● ●      | 12 2000×20 ● ● ● ●      | 12 1000×20 ● ● ● ●      | 12 1000×20 ● ● ● ●      |
|                         |                         | 16 1000×20 ● ● ● ●      | 16 500×20 ● ● ● ●       |
|                         |                         | 20 500×20 ● ● ● ●       | 20 500×20 ● ● ● ●       |
|                         |                         | 25 500×20 ● ● ● ●       | 25 500×20 ● ● ● ●       |
|                         |                         | 30 500×20 ● ● ● ●       | 30 300×20 ● ● ● ●       |
|                         |                         |                         | 30 500×14 ● ● ● ●       |