

M5.0					
長さ	入り数	鉄			ステンレス
		三浦ホワイト	三浦ブラック	ニッケル	
8	100×50	●	●	●	
10	100×50	●	●	●	
12	100×20				●
12	100×50	●			●
16	100×20				●
16	100×50	●			●
20	100×20				●
20	100×50	●			●
25	100×20				●
25	100×50	●			●
30	100×20				●
30	100×50	●			●

M6.0					
長さ	入り数	鉄			ステンレス
		三浦ホワイト	三浦ブラック	ニッケル	
10	100×50	●	●	●	
12	100×20				●
12	100×50	●			●
16	100×20				●
16	100×50	●			●
20	100×20				●
20	100×50	●			●
25	100×20				●
25	100×50	●			●
30	100×20				●
30	100×50	●			●

## 鉄 ⊕ 超極低頭ねじ (AHN-CT)

0000A010

鉄

3.0						
長さ	入り数	生地	クロメート	三浦ホワイト	三浦ブラック	ニッケル
4	2000×20	●	●	●	●	●
6	2000×20	●	●	●	●	●
8	2000×20	●	●	●	●	●
10	2000×20	●	●	●	●	●

## TRX スリムヘッド小ねじ




0000A400

鉄

0002A400

ステンレス

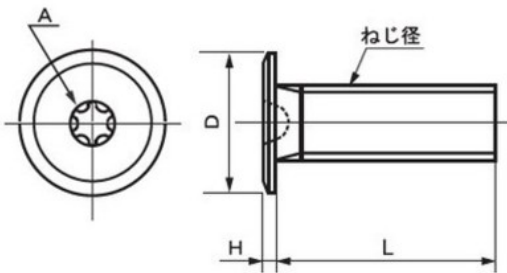

ねじの呼び	D		H		ドライブサイズ
	基準寸法	許容差	基準寸法	許容差	
M2	4.0	0 -0.5	0.5	±0.1	T4
M2.6	6.0		0.6		T5
M3	7.0		0.8		T6
M4	8.0		0.9		T8
M5	9.0		1.0		T10
M6	12.0		1.2		T20

M2.0					
長さ	入り数	鉄			ステンレス
		三浦ホワイト	三浦ブラック	ニッケル	
4	2000×20	●	●	●	●
5	2000×20	●	●	●	●
6	2000×20	●	●	●	●
8	2000×20	●	●	●	●
10	2000×20	●	●	●	●
12	2000×20	●	●	●	●

M2.6					
長さ	入り数	鉄			ステンレス
		三浦ホワイト	三浦ブラック	ニッケル	
4	2000×20	●	●	●	●
5	2000×20	●	●	●	●
6	2000×20	●	●	●	●
8	2000×20	●	●	●	●
10	2000×20	●	●	●	●
12	2000×20	●	●	●	●

M3.0					
長さ	入り数	鉄			ステンレス
		三浦ホワイト	三浦ブラック	ニッケル	
4	2000×20			●	
5	2000×20			●	
6	2000×20	●	●	●	●
8	2000×20	●	●	●	●
10	2000×20	●	●	●	●
12	1000×20	●	●	●	●
16	1000×20	●	●	●	●
20	500×20	●	●	●	●
25	500×20	●	●	●	●
30	500×20	●	●	●	●

M4.0					
長さ	入り数	鉄			ステンレス
		三浦ホワイト	三浦ブラック	ニッケル	
6	1000×20	●	●	●	●
8	1000×20	●	●	●	●
10	1000×20	●	●	●	●
12	1000×20	●	●	●	●
16	500×20	●	●	●	●
20	500×20	●	●	●	●
25	500×20	●	●	●	●
30	500×14	●	●	●	●