

# ⊕ ナベ P=2(SW組込)



10000002

10010002

10020002


10120002

鉄

黄銅

ステンレス

SUS 316L

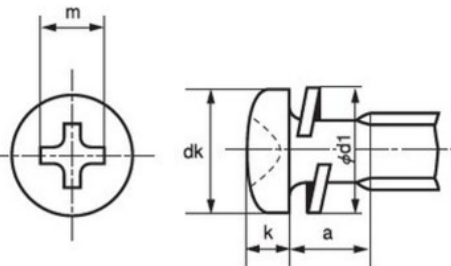

ねじの呼び	小ねじ本体					ばね座金	
	dk	k	十字穴		d1 (最大)	a	
			十字穴番号	m (参考)			
M2	3.5 <sup>0</sup> <sub>-0.4</sub>	1.3±0.1	1	2.2	4	1.8	
M2.3	4 <sup>0</sup> <sub>-0.4</sub>	1.5±0.1	1	2.4	4.6	2.0	
M2.5	4.5 <sup>0</sup> <sub>-0.4</sub>	1.7±0.1	1	2.6	4.8	2.1	
M2.6	4.5 <sup>0</sup> <sub>-0.4</sub>	1.7±0.1	1	2.6	4.8	2.1	
M3	5.5 <sup>0</sup> <sub>-0.5</sub>	2±0.15	2	3.6	5.5	2.4	
M3.5	6 <sup>0</sup> <sub>-0.5</sub>	2.3±0.15	2	3.9	6.2	2.8	
M4	7 <sup>0</sup> <sub>-0.5</sub>	2.6±0.15	2	4.2	7	3.5	
M5	9 <sup>0</sup> <sub>-0.6</sub>	3.3±0.15	2	4.9	8.5	4.3	
M6	10.5 <sup>0</sup> <sub>-0.7</sub>	3.9±0.2	3	6.3	11.5	5.1	
M8	14 <sup>0</sup> <sub>-0.8</sub>	5.2±0.2	3	7.8	14.5	6.7	
M10	19 <sup>0</sup> <sub>-1.5</sub>	6±1	4	9.4	17.5	8.2	

		M2.0																	
長さ	入り数	鉄											黄銅	ステンレス					
		生地	クロロ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	亜鉛黒	黒ツヤケル	Zn-Ni(55%)	Zn-Ni(50%)	Al	生地	ニッケル	生地	ステンレス		
3	10000×20																		
3	9000×20																		
4	8000×20																		
5	7000×20																		
5	8000×20																		
6	6000×20																		
6	7000×20																		
7	5000×20																		
8	5000×20																		
8	6000×20																		
10	4000×20																		
10	5000×20																		
12	3500×20																		
12	4000×20																		
14	3000×20																		
15	2500×20																		
15	3000×20																		
16	2500×20																		
18	2000×20																		
19	2000×20																		
20	2000×20																		
25	600×20																		

		M2.3																	
長さ	入り数	鉄											黄銅	ステンレス					
		生地	クロロ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	亜鉛黒	黒ツヤケル	Zn-Ni(55%)	Zn-Ni(50%)	Al	生地	ニッケル	生地	ステンレス		
4	5000×20																		
4	5500×20																		
5	5000×20																		
6	5000×20																		
8	4000×20																		
10	3000×20																		
10	3500×20																		
12	2500×20																		
12	3000×20																		
14	2000×20																		
14	2500×20																		
15	2000×20																		
16	2000×20																		
18	1800×20																		
18	2000×20																		
20	1500×20																		