

⊕ ナベ P=4(SW+JIS小形W組込)



小ねじ

マフロねじ

組込みねじ

タツピンねじ

タツタイト・
ハイテックねじ

いたすら防止ねじ

建材用スクリュー

ボルト

キャップホーロー

ドリルねじ

座金

つまみねじ

ナット

樹脂製品

アンカーボルト

10000004

鉄

10010004


黄銅

10020004

ステンレス

10120004

SUS 316L

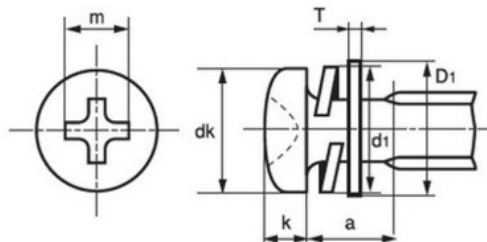

ねじの 呼び	小ねじ本体					平座金 D1×T	ばね座金	
	dk	k	十字穴		d1 (最大)		a	
			十字穴 番号	m (参考)				
M2	3.5	$\begin{smallmatrix} 0 \\ -0.4 \end{smallmatrix}$	1.3±0.1	1	2.2	4.3×0.4	4	2.2
M2.3	4	$\begin{smallmatrix} 0 \\ -0.4 \end{smallmatrix}$	1.5±0.1	1	2.4	4.6×0.4	4.6	2.4
M2.6	4.5	$\begin{smallmatrix} 0 \\ -0.4 \end{smallmatrix}$	1.7±0.1	1	2.6	5×0.5	4.8	2.7
M3	5.5	$\begin{smallmatrix} 0 \\ -0.5 \end{smallmatrix}$	2±0.15	2	3.6	6×0.5	5.5	3.0
M3.5	6	$\begin{smallmatrix} 0 \\ -0.5 \end{smallmatrix}$	2.3±0.15	2	3.9	7×0.5	6.2	3.4
M4	7	$\begin{smallmatrix} 0 \\ -0.5 \end{smallmatrix}$	2.6±0.15	2	4.2	8×0.5	7	4.1
M5	9	$\begin{smallmatrix} 0 \\ -0.6 \end{smallmatrix}$	3.3±0.15	2	4.9	10×0.8	8.5	5.2
M6	10.5	$\begin{smallmatrix} 0 \\ -0.7 \end{smallmatrix}$	3.9±0.2	3	6.3	11.5×0.8	11.5	6.1
M8	14	$\begin{smallmatrix} 0 \\ -0.8 \end{smallmatrix}$	5.2±0.2	3	7.8	16×1.2	14.5	8.0

M2.0																
長さ	入り数	鉄														
		生地	マフロ	クロメート	三価クロム	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキW	メッキ黒	メッキ白	メッキ黄	メッキ青	メッキ赤	メッキ紫
3	7000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	7000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	6000×20															
6	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
7	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×20															
9	3500×20					●										
10	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	4000×20															
12	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	3500×20															
14	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	3000×20															
15	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	2500×20															
16	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2500×20															
18	1500×20															
18	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	2000×20															
20	1500×20															
20	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	2000×20															
25	1000×24															
25	1200×20	●	●	●												

M2.3				
長さ	入り数	黄銅		
		生地	ニッケル	ステンレス
8	3500×20	●	●	