


# ⊕ ナベ I=3 (SW+ISO W組込)



小ねじ  
マフロねじ  
組込みねじ  
タツピンねじ  
タツタイト  
ハイエタねじ  
いたすら防止ねじ  
建材用スクリュー  
ボルト  
キャップボルト  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト

10000013 鉄	10010013 黄銅	10020013 ステンレス
---------------	----------------	-------------------

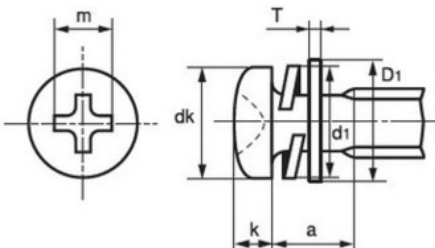

ねじの呼び	小ねじ本体				平座金 D1×T	ばね座金	
	dk	k	十字穴			d1 (最大)	a
			十字穴 番号	m (参考)			
M2	3.5 $0$ -0.4	1.3±0.1	1	2.2	5×0.3	4	2.1
M2.3	4 $0$ -0.4	1.5±0.1	1	2.4	6.5×0.5	4.6	2.5
M2.5	4.5 $0$ -0.4	1.7±0.1	1	2.6	6.5×0.5	4.8	2.7
M2.6	4.5 $0$ -0.4	1.7±0.1	1	2.6	6.5×0.5	4.8	2.7
M3	5.5 $0$ -0.5	2±0.15	2	3.6	7×0.5	5.5	3.0
M3.5	6 $0$ -0.5	2.3±0.15	2	3.9	9×0.5	6.2	3.4
M4	7 $0$ -0.5	2.6±0.15	2	4.2	9×0.8	7	4.4
M5	9 $0$ -0.6	3.3±0.15	2	4.9	10×1.0	8.5	5.4
M6	10.5 $0$ -0.7	3.9±0.2	3	6.3	12.5×1.6	11.5	6.9
M8	14 $0$ -0.8	5.2±0.2	3	7.8	17×1.6	14.5	8.4

		M2.0																
長さ	入り数	鉄											黄銅	ステンレス				
		生地	メテロ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキ	メッキ	生地	ニッケル	生地	PKフラッシュ		
3	6000×20																	
4	6000×20																	
5	5000×20																	
6	4000×20																	
6	5000×20																	
7	4000×20																	
8	4000×20																	
10	3000×20																	
10	3500×20																	
12	2500×20																	
12	3000×20																	
14	2000×20																	
14	2200×20																	
14	2500×20																	
15	2000×20																	
15	2500×20																	
16	2000×20																	
18	1500×20																	
18	1800×20																	
18	2000×20																	
20	1500×20																	

		M2.3																
長さ	入り数	鉄											黄銅	ステンレス				
		生地	メテロ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキ	メッキ	生地	ニッケル	生地	PKフラッシュ		
4	3500×20																	
5	3000×20																	
6	3000×20																	
8	2500×20																	
10	2000×20																	
10	2500×20																	
12	1800×20																	
12	2000×20																	

		M2.5																
長さ	入り数	鉄											黄銅	ステンレス				
		生地	メテロ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	亜鉛黒	黒ニッケル	メッキ	メッキ	生地	ニッケル	生地	PKフラッシュ		
4	2500×20																	
4	3000×20																	
5	2500×20																	
6	2000×20																	
6	2200×20																	
6	2500×20																	
8	2000×20																	
8	2500×20																	
10	1500×20																	
10	1800×20																	
10	2000×20																	
12	1500×20																	
12	2000×20																	
14	1000×20																	
14	1200×20																	
14	1500×20																	
15	1000×20																	
15	1200×20																	
15	1500×20																	
16	1000×20																	
16	1200×20																	
16	1500×20																	
18	1000×20																	
20	1000×20																	
25	800×20																	
30	600×20																	
35	500×20																	
40	400×20																	
45	350×20																	