


⊕ ナベ l=4 (SW+ISO小形W組込)



10000014	10010014	10020014
鉄	黄銅	ステンレス

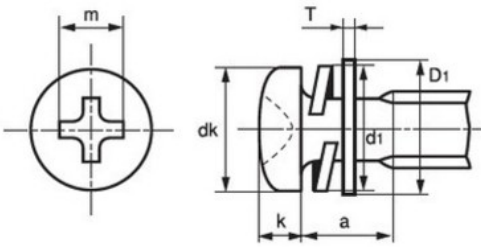

ねじの呼び	小ねじ本体				平座金 D1×T	ばね座金	
	dk	k	十字穴			d1 (最大)	a
			十字穴 番号	m (参考)			
M2	3.5 <sup>0</sup> <sub>-0.4</sub>	1.3±0.1	1	2.2	4.3×0.3	4	2.1
M2.3	4 <sup>0</sup> <sub>-0.4</sub>	1.5±0.1	1	2.4	4.6×0.5	4.6	2.5
M2.5	4.5 <sup>0</sup> <sub>-0.4</sub>	1.7±0.1	1	2.6	5×0.5	4.8	2.7
M2.6	4.5 <sup>0</sup> <sub>-0.4</sub>	1.7±0.1	1	2.6	5×0.5	4.8	2.7
M3	5.5 <sup>0</sup> <sub>-0.5</sub>	2±0.15	2	3.6	6×0.5	5.5	3.0
M3.5	6 <sup>0</sup> <sub>-0.5</sub>	2.3±0.15	2	3	7×0.5	6.2	3.4
M4	7 <sup>0</sup> <sub>-0.5</sub>	2.6±0.15	2	4.2	8×0.8	7	4.4
M5	9 <sup>0</sup> <sub>-0.6</sub>	3.3±0.15	2	2	10×1.0	8.5	5.4
M6	10.5 <sup>0</sup> <sub>-0.7</sub>	3.9±0.2	3	6.3	11.5×1.6	11.5	6.9
M8	14 <sup>0</sup> <sub>-0.8</sub>	5.2±0.2	3	7.8	15.5×1.6	14.5	8.4

		M2.0																
長さ	入り数	鉄												黄銅		ステンレス		
		生地	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒メタル	メッキ	メッキ	メッキ	メッキ	生地	ニッケル	生地	ステンレス	
4	7000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	6000×20																	
6	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
7	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×20																	
10	3000×20																	
10	3500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20																	
12	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	3500×20																	
14	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	3000×20																	
15	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	2500×20																	
16	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2500×20																	
20	2000×20																	

		M2.3																
長さ	入り数	鉄												ステンレス				
		生地	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒メタル	メッキ	メッキ	メッキ	メッキ	生地	ステンレス			
4	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	5000×20																	
6	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	5000×20																	
8	3500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	4000×20																	
10	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×20																	
12	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20																	
14	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	1200×20																	