

⊕ ⊖ ナベ P=4 (SW+JIS小形W組込)



10000204


鉄

10010204

黄銅

10020204

ステンレス

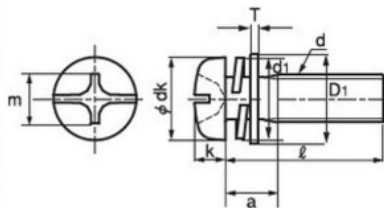

ねじの呼び (d)	ピッチ P	十字穴の番号	dk		k		m	平座金 D1×T	ばね座金 d1 (最大)	a
			基準寸法	許容差	基準寸法	許容差				
M3	0.5	2	5.5	0	2	±0.15	3.6	6×0.5	5.5	3.0
M4	0.7		7	-0.5	2.6		4.2	8×0.5	7	4.1
M5	0.8		9	0 -0.6	3.3		4.9	10×0.8	8.5	5.2
M6	1.0	3	10.5	0 -0.7	3.9	±0.2	6.3	11.5×0.8	11.5	6.1

M3.0

長さ	入り数	鉄							ステンレス
		生地	クロメート	クロムメイト	三価ホウ酸	三価フッ素	ニッケル	亜鉛黒	
4	2000×20	●	●	●	●	●	●	●	●
5	2000×20	●	●	●	●	●	●	●	●
6	2000×20	●	●	●	●	●	●	●	●
6	2000×24								●
8	1800×20	●	●	●	●	●	●	●	●
8	2000×18								●
10	1500×20	●	●	●	●	●	●	●	●
10	2000×18								●
12	1000×24								●
12	2000×14	●	●	●	●	●	●	●	●
14	1000×24								●
14	1800×14								●
16	1500×14	●	●	●	●	●	●	●	●
20	1200×14	●	●	●	●	●	●	●	●

M3.5

長さ	入り数	鉄							ステンレス	
		生地	クロメート	クロムメイト	三価ホウ酸	三価フッ素	ニッケル	クロム		亜鉛黒
6	2000×18									●
7	2000×14	●	●	●	●	●	●	●	●	●
8	1000×24									●
10	1000×24									●
10	1800×14	●	●	●	●	●	●	●	●	●
12	1000×24									●

M4.0

長さ	入り数	鉄							黄銅		ステンレス
		生地	クロメート	クロムメイト	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	メッキなし	
6	1500×14	●	●	●	●	●	●	●	●	●	●
8	1000×24										●
8	1300×14	●	●	●	●	●	●	●	●	●	●
8	1500×14									●	●
10	1000×18										●
10	1200×14	●	●	●	●	●	●	●	●	●	●
12	1000×14	●	●	●	●	●	●	●	●	●	●
12	1000×18										●
14	900×14	●	●	●	●	●	●	●	●	●	●
15	1000×18										●
15	900×14	●	●	●	●	●	●	●	●	●	●
16	500×24										●
16	800×14	●	●	●	●	●	●	●	●	●	●
18	800×14	●	●	●	●	●	●	●	●	●	●
20	700×14	●	●	●	●	●	●	●	●	●	●
22	700×14	●	●	●	●	●	●	●	●	●	●
25	600×14	●	●	●	●	●	●	●	●	●	●
30	500×14	●	●	●	●	●	●	●	●	●	●
35	400×14	●	●	●	●	●	●	●	●	●	●

M5.0

長さ	入り数	鉄							ステンレス		
		生地	クロメート	クロムメイト	三価ホウ酸	三価フッ素	ニッケル	クロム		亜鉛黒	メッキなし
8	800×14	●	●	●	●	●	●	●	●	●	●
10	500×18										●
10	700×14	●	●	●	●	●	●	●	●	●	●
12	500×18										●
12	600×14	●	●	●	●	●	●	●	●	●	●
14	500×14	●	●	●	●	●	●	●	●	●	●
15	500×14	●	●	●	●	●	●	●	●	●	●
16	500×14	●	●	●	●	●	●	●	●	●	●
16	500×18										●
18	450×14	●	●	●	●	●	●	●	●	●	●
20	400×14	●	●	●	●	●	●	●	●	●	●
22	500×10	●	●	●	●	●	●	●	●	●	●
25	200×24										●
25	500×10	●	●	●	●	●	●	●	●	●	●
30	500×10	●	●	●	●	●	●	●	●	●	●
35	400×10	●	●	●	●	●	●	●	●	●	●

M6.0

長さ	入り数	鉄							ステンレス	
		生地	クロメート	クロムメイト	三価ホウ酸	三価フッ素	ニッケル	亜鉛黒		メッキなし
10	400×14	●	●	●	●	●	●	●	●	●
12	400×14	●	●	●	●	●	●	●	●	●
14	350×14	●	●	●	●	●	●	●	●	●
15	350×14	●	●	●	●	●	●	●	●	●
16	350×14	●	●	●	●	●	●	●	●	●
18	300×14	●	●	●	●	●	●	●	●	●
20	300×14	●	●	●	●	●	●	●	●	●
25	350×10	●	●	●	●	●	●	●	●	●
30	350×10	●	●	●	●	●	●	●	●	●
35	100×24									●

M8.0

長さ	入り数	鉄	
		クロメート	三価ホウ酸
15	150×14	●	●