

小ねじ

マフロねじ

組込みねじ

タッピンねじ

タツタイト・
ハイエックねじ

いたすら防止ねじ

建材用スクリュー

ボルト

キャップホーロー

ドリルねじ

座金

つまみねじ

ナット

樹脂製品

アンカーボルト

M3.0										
長さ	入り数	鉄								ステンレス
		生地	クロメート	三価ホフ	三価フタ	ニッケル	クロム	亜鉛黒	ヘキサホフ	ヘキサフタ
4	1800×20			●					●	
5	1500×20		●	●	●	●	●	●	●	●
6	1500×20	●	●	●	●	●	●	●	●	●
6	2000×18									●
8	1200×20		●	●	●	●	●	●	●	●
8	2000×18									●
10	1000×24									●
10	1200×20		●	●	●	●	●	●	●	●
12	1600×14		●	●	●	●	●	●	●	●
14	1500×14			●					●	●
15	1500×14			●					●	●
16	1400×14		●	●	●	●	●	●	●	●
20	1000×14				●				●	●
25	900×14			●					●	●
30	700×14			●					●	●

M4.0										
長さ	入り数	鉄								ステンレス
		生地	クロメート	三価ホフ	三価フタ	ニッケル	クロム	亜鉛黒	ヘキサホフ	ヘキサフタ
6	1000×18									●
6	1200×14		●	●	●	●	●	●	●	●
8	1000×14		●	●	●	●	●	●	●	●
8	1000×18									●
10	1000×18									●
10	900×14		●	●	●	●	●	●	●	●
12	500×24									●
12	900×14		●	●	●	●	●	●	●	●
14	800×14			●						●
15	700×14		●	●	●	●	●	●	●	●
16	700×14		●	●	●	●	●	●	●	●
18	600×14		●	●	●	●	●	●	●	●
20	600×14		●	●	●	●	●	●	●	●
25	500×14			●					●	●
35	300×14			●					●	●

M5.0										
長さ	入り数	鉄								ステンレス
		クロメート	クロメート	三価ホフ	三価フタ	ニッケル	クロム	亜鉛黒	ヘキサホフ	ヘキサフタ
8	600×14	●	●	●	●	●	●	●	●	●
10	500×18									●
10	600×14	●	●	●	●	●	●	●	●	●
12	500×14	●	●	●	●	●	●	●	●	●
12	500×18									●
14	500×14	●	●	●	●	●	●	●	●	●
15	450×14	●	●	●	●	●	●	●	●	●
16	450×14	●	●	●	●	●	●	●	●	●
16	500×18									●
18	400×14	●	●	●	●	●	●	●	●	●
20	400×14	●	●	●	●	●	●	●	●	●
25	450×10	●	●	●	●	●	●	●	●	●
30	400×10			●					●	●

M6.0										
長さ	入り数	鉄								ステンレス
		クロメート	クロメート	三価ホフ	三価フタ	ニッケル	クロム	亜鉛黒	ヘキサホフ	ヘキサフタ
10	400×14			●					●	●
12	200×24									●
12	350×14	●	●	●	●	●	●	●	●	●
15	300×14			●					●	●
16	300×14			●					●	●


⊕ ナベ P=4(薄板用) (SW+JIS小形W組込)

1000U004

鉄

1002U004

ステンレス

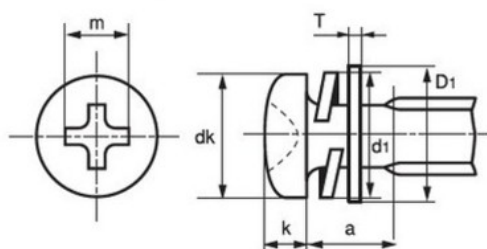

ねじの呼び (d)	小ねじ本体				平座金 外径×厚み (D1×T)	ばね座金 外径 d1 (最大)	座面から 完全ネジ 部までの 最大値(a)
	頭径 (dk)	頭高 (k)	十字穴				
			十字穴 番号	翼長さm (参考)			
M3	5.5 0 −0.5	2±0.15	2	3.6	6×0.5	5.5	1.8
M4	7 0 −0.5	2.6±0.15	2	4.2	8×0.5	7	2.4
M5	9 0 −0.6	3.3±0.15	2	4.9	10×0.8	8.5	3.3

M3.0										
長さ	入り数	鉄								ステンレス
		生地	クロメート	三価ホフ	三価フタ	ニッケル	クロム	亜鉛黒	ヘキサホフ	ヘキサフタ
5	2000×20		●	●	●	●	●	●	●	●
6	2000×20		●	●	●	●	●	●	●	●
6	2000×24									●
8	1800×20	●	●	●	●	●	●	●	●	●
8	2000×18									●
10	1500×20		●	●	●	●	●	●	●	●
12	2000×14		●	●	●	●	●	●	●	●
15	1500×14		●	●	●	●	●	●	●	●
16	1500×14		●	●	●	●	●	●	●	●

M4.0										
長さ	入り数	鉄								ステンレス
		生地	クロメート	三価ホフ	三価フタ	ニッケル	クロム	亜鉛黒	ヘキサホフ	ヘキサフタ
6	1500×14	●	●	●	●	●	●	●	●	●
8	1000×24									●
8	1300×14		●	●	●	●	●	●	●	●
10	1000×18									●
10	1200×14	●	●	●	●	●	●	●	●	●
12	1000×14	●	●	●	●	●	●	●	●	●
12	1000×18									●
14	1000×18									●
14	900×14			●					●	●
15	900×14	●	●	●	●	●	●	●	●	●
16	800×14		●	●	●	●	●	●	●	●
18	800×14		●	●	●	●	●	●	●	●
20	700×14		●	●	●	●	●	●	●	●
25	500×18									●

M5.0										
長さ	入り数	鉄								ステンレス
		クロメート	クロメート	三価ホフ	三価フタ	ニッケル	クロム	亜鉛黒	ヘキサホフ	ヘキサフタ
8	800×14	●	●	●	●	●	●	●	●	●
10	700×14	●	●	●	●	●	●	●	●	●
12	600×14	●	●	●	●	●	●	●	●	●
14	500×14	●	●	●	●	●	●	●	●	●
15	500×14	●	●	●	●	●	●	●	●	●
16	500×14			●					●	●
20	400×14	●	●	●	●	●	●	●	●	●