

⊕ 六角アプセット P=2 (SW組込)

		M8.0																			
長さ	入り数	鉄											ステンレス								
		生地	クロム	クロム	三鋼ホワイト	三鋼ブラック	マテ	クロム	亜鉛黒	ダクロ	グリーン	三層セラ	NDH	NDH	NDH	NDH	NDH	NDH	生地	SC3	SC4
10	100×24																		●	●	●
12	100×24																		●	●	●
12	200×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
14	100×24																		●	●	●
14	200×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
15	100×24																		●	●	●
15	150×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
16	100×24																		●	●	●
16	150×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
18	100×24																		●	●	●
18	150×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
20	100×24																		●	●	●
20	150×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
22	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
25	100×18																		●	●	●
25	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
30	100×18																		●	●	●
30	150×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
35	170×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
35	50×24																		●	●	●
40	120×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
40	50×24																		●	●	●
45	120×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
45	50×24																		●	●	●
50	100×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
50	50×18																		●	●	●
55	100×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
60	80×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
65	80×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
70	70×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			
75	70×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●			


		M10.0												
長さ	入り数	鉄							ステンレス					
		生地	クロム	クロム	三鋼ホワイト	三鋼ブラック	マテ	亜鉛黒	生地	SC3	SC4			
16	120×10													
20	100×10	●	●	●	●	●	●	●	●	●	●	●	●	●
20	50×24													
25	100×10	●	●	●	●	●	●	●	●	●	●	●	●	●
25	50×24													
30	100×10	●	●	●	●	●	●	●	●	●	●	●	●	●
30	50×18													
35	100×10	●	●	●	●	●	●	●	●	●	●	●	●	●
35	50×18													
40	80×10	●	●	●	●	●	●	●	●	●	●	●	●	●
45	80×10	●	●	●	●	●	●	●	●	●	●	●	●	●
50	70×10	●	●	●	●	●	●	●	●	●	●	●	●	●

		M12.0					
長さ	入り数	鉄					
		クロム	クロム	三鋼ホワイト	三鋼ブラック	マテ	亜鉛黒
25	80×10	●	●	●	●	●	●
30	60×10	●	●	●	●	●	●
35	50×10						
40	50×10	●	●	●	●	●	●

⊕ 六角アプセット P=3 (SW+JIS W組込)



10000103	10010103	10020103
鉄	黄銅	ステンレス

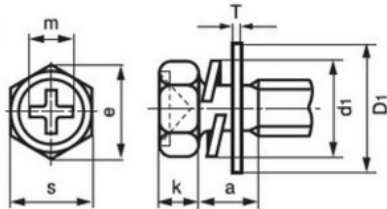

ねじの呼び (d)	K		S		e (約)	十字穴		平座金 D1×T	ばね座金 d1 (最大)	a
	基準寸法	許容差	基準寸法	許容差		番号	m (参考)			
M3	2.0	±0.1	5.5	0	6.05	2	3.5	8×0.5	5.5	3.0
M4	2.8		7		7.7	2	4	10×0.8	7	4.4
M5	3.5	±0.15	8	-0.2	8.7	2	4.8	12×0.8	8.5	5.2
M6	4.0		10		10.9	3	6.2	13×1.0	11.5	6.3
M8	5.5	±0.2	13	-0.25	14.1	3	7.2	18×1.6	14.5	8.4
M10	7.0		17		18.9	4	9.25	22×1.6	17.5	10.0