

# ⊕ 六角アプセット P=4 (SW+JIS小形W組込)



10000104


鉄

10010104

黄銅

10020104

ステンレス

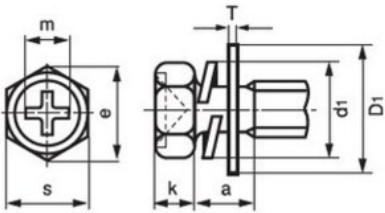

ねじの呼び (d)	K		S		e (約)	十字穴		平座金 D1×T	ばね座金 d1 (最大)	a
	基準寸法	許容差	基準寸法	許容差		番号	m (参考)			
M3	2	±0.1	5.5	0	6.05	2	3.5	6×0.5	5.5	3.0
M4	2.8		7		7.7	2	4	8×0.5	7	4.1
M5	3.5		8		8.7	2	4.8	10×0.8	8.5	5.2
M6	4		10		10.9	3	6.2	11.5×0.8	11.5	6.1
M8	5.5	±0.15	13	0	14.1	3	7.2	16×1.2	14.5	8.0
				-0.25						

### M3.0

長さ	入り数	鉄														ステンレス	
		生地	クロメート	三価ホウ酸	三価クロム	ニッケル	クロム	亜鉛黒	グリーン	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	SC303
5	1500×20																
5	2000×18																
6	1500×20																
6	2000×18																
8	1000×24																
8	1500×20																
10	1000×24																
10	1500×20																
12	1000×18																
12	1600×14																
14	1500×14																
15	1200×14																
16	1200×14																
20	900×14																

### M4.0

長さ	入り数	鉄														黄銅		ステンレス	
		生地	クロメート	三価ホウ酸	三価クロム	ニッケル	クロム	亜鉛黒	グリーン	メッキ	メッキ	メッキ	メッキ	メッキ	生地	SC303			
6	1000×14																		
6	500×24																		
8	1000×14																		
8	500×24																		
10	500×24																		
10	800×14																		
12	500×24																		
12	800×14																		
14	700×14																		
15	500×18																		
15	700×14																		
16	500×18																		
16	700×14																		
18	600×14																		
20	500×14																		
20	500×18																		
25	500×14																		
30	400×14																		
35	300×14																		
40	400×10																		
45	350×10																		
50	300×10																		

### M5.0

長さ	入り数	鉄														ステンレス	
		生地	クロメート	三価ホウ酸	三価クロム	ニッケル	クロム	亜鉛黒	グリーン	メッキ	メッキ	メッキ	メッキ	メッキ	生地	SC303	
8	500×24																
8	700×14																
10	500×24																
10	600×14																
12	500×14																
12	500×18																
13	500×14																
14	500×14																
15	500×14																
15	500×18																
16	500×14																
16	500×18																
18	200×24																
18	400×14																
20	200×24																
20	400×14																
25	200×24																
25	500×10																
28	400×10																
30	400×10																
35	350×10																
40	300×10																
45	250×10																
50	200×10																

### M6.0

長さ	入り数	鉄														ステンレス	
		生地	クロメート	三価ホウ酸	三価クロム	ニッケル	クロム	亜鉛黒	グリーン	メッキ	メッキ	メッキ	メッキ	メッキ	生地	SC303	
10	400×14																
12	200×24																
12	350×14																
14	350×14																
15	200×24																
15	350×14																
16	200×24																
16	300×14																
18	300×14																
20	200×24																
20	300×14																
22	350×10																
25	200×18																
25	350×10																
28	300×10																
30	100×24																
30	300×10																
35	250×10																
40	200×10																
45	200×10																
50	200×10																