

# ⊕ 六角アプセット l=1 (ISO W組込)




10000111

鉄

10010111

黄銅

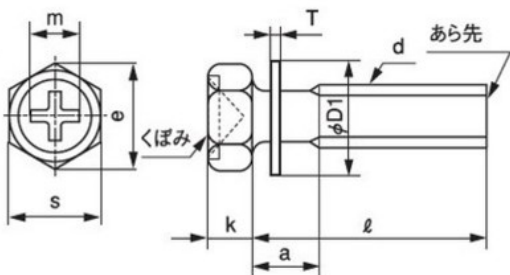

ねじの呼び (d)	K		S		e (約)	十字穴の番号	m (参考)	平座金 D1×T	a
	基準寸法	許容差	基準寸法	許容差					
M5	3.5	±0.15	8	0 -0.2	8.7	2	4.9	10×1.0	2.7


M5.0			
長さ	入り数	鉄	黄銅
10	600×14	●	
10	700×14		●

# 鉄 ⊕ 六角アプセット l=3 (SW+ISO W組込)



10000113

鉄

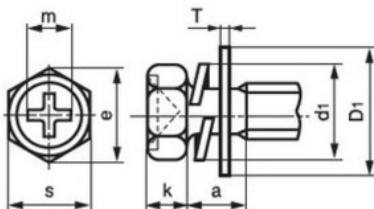

ねじの呼び (d)	K		S		e (約)	十字穴		平座金 D1×T	ばね座金 d1 (最大)	a
	基準寸法	許容差	基準寸法	許容差		番号	m (参考)			
M3	2	±0.1	5.5	0 -0.2	6.05	2	3.5	7×0.5	5.5	3.0
M4	2.8		7		7.7	2	4	9×0.8	7	4.4
M5	3.5		8		8.7	2	4.8	10×1.0	8.5	5.4
M6	4	±0.15	10	0	10.9	3	6.2	12.5×1.6	11.5	6.9
M8	5.5		13		14.1	3	7.2	17×1.6	14.5	8.4
M10	7	±0.2	17	-0.25	18.9	4	9.25	21×2.0	17.5	10.4

M3.0										
長さ	入り数	ユアロ	クロメート	三価ホウフ	ニッケル	亜鉛黒	ステンレス	ステンレス	ステンレス	ステンレス
6	1500×20	●	●	●	●	●	●	●	●	●
8	1200×20	●	●	●	●	●	●	●	●	●
10	1000×20	●	●	●	●	●	●	●	●	●
12	1500×14	●	●	●	●	●	●	●	●	●
20	900×14	●	●	●	●	●	●	●	●	●

M4.0										
長さ	入り数	ユアロ	クロメート	三価ホウフ	ニッケル	亜鉛黒	ステンレス	ステンレス	ステンレス	ステンレス
6	1000×14	●	●	●	●	●	●	●	●	●
8	1000×14	●	●	●	●	●	●	●	●	●
10	800×14	●	●	●	●	●	●	●	●	●
12	800×14	●	●	●	●	●	●	●	●	●
15	700×14	●	●	●	●	●	●	●	●	●
16	700×14	●	●	●	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●	●
35	300×14	●	●	●	●	●	●	●	●	●