

# 鋼 7マーク小形六角アプセット細目 SP=3(SPAK+JIS W組込)



100076S3

鉄

## M10.0

長さ の呼び	入り 数	クロ メート
30	80×10	●
35	80×10	●

# 六角トリーマ P=1 (JIS W組込)




11000001

鉄

11020001

ステンレス

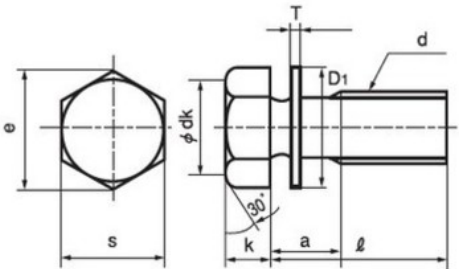

ねじの 呼び (d)	k		s		e (約)	dk (約)	平座金 D1×T	a
	基準 寸法	許容差	基準 寸法	許容差				
M4	2.8	±0.1	7	0 -0.2	8.1	6.8	10×0.8	2.3
M5	3.5	±0.15	8		9.2	7.8	12×0.8	2.5
M6	4		10	11.5	9.8	13×1.0	3.1	
M8	5.5	±0.2	13	0 -0.25	15.0	12.6	18×1.6	4.2
M10	7		17	19.6	16.5	22×1.6	4.8	
M12	8		19	0 -0.35	21.9	18	26×2.3	6.0
M16	10	24	27.7	23	32×2.6	7.1		

M4.0							
長さ の呼び	入り 数	鉄			ステンレス		
		エ ポ ク ロ	ク ロ メ ー ト	三 価 クロ メ ー ト	生 地	SC 3	SC 4
8	500×24				●	●	●
10	500×24				●	●	●
12	500×24				●	●	●
12	800×14	●	●	●			
14	500×18				●		
15	500×18				●		
16	500×18				●		
18	500×18				●		
20	500×18				●		
25	200×24				●		
30	200×24				●		
45	300×10	●	●				

M5.0												
長さ の呼び	入り 数	鉄							ステンレス			
		生 地	エ ポ ク ロ	ク ロ メ ー ト	三 価 クロ メ ー ト	三 価 クロ メ ー ト	ニ ッケ ル	亜 鉛 黒	ダ ク ロ	生 地	SC 3	SC 4
8	500×18									●		
8	600×14	●	●	●								
10	500×14	●	●	●	●	●	●					
10	500×18								●	●	●	●
12	500×14	●	●	●	●	●	●		●	●	●	●
14	450×14	●	●	●	●	●	●					
14	500×14								●			
15	400×14	●	●	●	●	●	●					
15	500×14								●			
16	400×14	●	●	●	●	●	●	●				
16	500×14								●	●	●	●
18	200×24								●			
18	350×14	●	●	●	●	●	●					
20	200×24								●			
20	350×14	●	●	●	●	●	●	●				
20	500×10								●			
25	200×24								●			
25	500×10	●	●	●	●	●	●	●				
30	200×18								●			
30	400×10	●	●	●	●	●	●	●				
40	100×24								●			

小ねじ  
マフロねじ  
組込みねじ  
タツピンねじ  
ツイタイト  
ハイテクねじ  
いたすら防止ねじ  
建材用スクリュー  
ボルト  
キャップボルト  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト