


M16.0						
長さ mm	入り 数	鉄				
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	亜鉛黒
35	40×10	●	●	●	●	●
40	35×10	●	●	●	●	●
45	30×10	●	●	●	●	●
50	30×10	●	●	●	●	●
55	30×10	●	●	●	●	●
65	25×10	●	●	●	●	●
70	25×10	●	●	●	●	●
75	25×10	●	●	●	●	●

## 六角トリーマ P=3(SW+JIS W組込)



11000003 鉄	11020003 ステンレス
---------------	-------------------

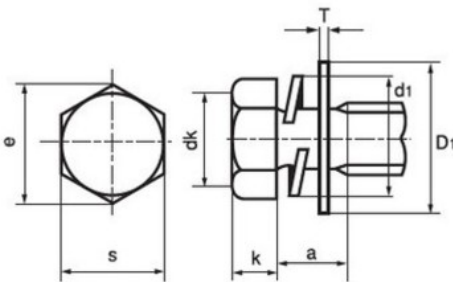

ねじの 呼び (d)	k		s		e (約)	dk (約)	平座金 D1×T	ばね座金 d1 (最大)	a
	基準 寸法	許容差	基準 寸法	許容差					
M3	2	±0.1	5.5	0 -0.2	6.4	5.3	8×0.5	5.5	3.0
M4	2.8	±0.1	7	0 -0.2	8.1	6.8	10×0.8	7	4.4
M5	3.5	±0.15	8	0 -0.2	9.2	7.8	12×0.8	8.5	5.2
M6	4		10		11.5	9.8	13×1.0	11.5	6.3
M8	5.5	±0.2	13	0 -0.25	15	12.6	18×1.6	14.5	8.4
M10	7		17		19.6	16.5	22×1.6	17.5	10.0
M12	8	±0.35	19	0 -0.35	21.9	18	26×2.3	20.5	12.3
M16	10		24		27.7	23	32×2.6	26.5	15.6

M3.0										
長さ mm	入り 数	鉄							ステンレス	
		生地	クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	亜鉛黒	ドブ	生地
6	1500×20	●	●	●	●	●	●	●	●	●
6	2000×18								●	●
8	1200×20	●	●	●	●	●	●	●	●	●
8	2000×18								●	●
10	1000×20	●	●	●	●	●	●	●	●	●
10	1000×24								●	●
10	2000×15								●	●
12	1000×24								●	●
12	1500×14	●	●	●	●	●	●	●	●	●
12	2000×15								●	●
14	1000×18								●	●
14	1000×20								●	●
15	1000×18								●	●
16	1000×18								●	●
18	1000×18								●	●
20	1000×18								●	●
22	500×24								●	●
25	500×24								●	●
30	500×18								●	●

M4.0													
長さ mm	入り 数	鉄							ステンレス				
		生地	クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	亜鉛黒	ドブ	生地	SC-3	SC-4
6	500×24									●	●	●	●
8	1000×14	●	●	●	●	●	●	●	●	●	●	●	●
8	500×24									●	●	●	●
10	500×24									●	●	●	●
10	800×14	●	●	●	●	●	●	●	●	●	●	●	●
12	500×24									●	●	●	●
12	800×14	●	●	●	●	●	●	●	●	●	●	●	●
14	500×18									●	●	●	●
14	700×14	●	●	●	●	●	●	●	●	●	●	●	●
15	500×18									●	●	●	●
15	700×14	●	●	●	●	●	●	●	●	●	●	●	●
16	500×18									●	●	●	●
16	700×14	●	●	●	●	●	●	●	●	●	●	●	●
18	500×18									●	●	●	●
18	600×14	●	●	●	●	●	●	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●	●	●	●	●
20	500×18									●	●	●	●
25	200×24									●	●	●	●
25	500×14	●	●	●	●	●	●	●	●	●	●	●	●
30	200×24									●	●	●	●
30	400×14	●	●	●	●	●	●	●	●	●	●	●	●
35	200×24									●	●	●	●
40	200×24									●	●	●	●
45	200×18									●	●	●	●
50	200×18									●	●	●	●

小ねじ  
マフロねじ  
組込みねじ  
タッピンねじ  
ハイテックねじ  
ツツタイト  
いたすら防止ねじ  
建材用スクリュー  
ボルト  
キャップボルト  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト