


⊕ 皿タップピンねじ(1種 A形)



20000001 鉄	20020001 ステンレス	20030001 SUS 410	20120001 SUS 316L	20190001 SUS ミラクル	20090001 チタン
---------------	-------------------	---------------------	----------------------	----------------------	-----------------

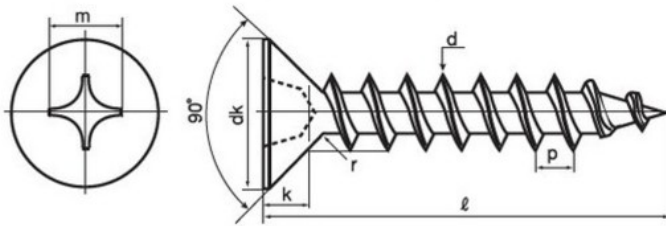

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	8	
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0	16.0	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	0 -0.8	
k	基準寸法	1.20	1.35	1.45	1.50	1.75	2.00	2.30	2.55	2.80	3.40	4.40	
	許容差	0 -0.2				0 -0.3					0 -0.4		
十字穴	m	参考	2.2	2.4	2.6	2.6	3.6	4.1	4.5	4.9	5.1	6.7	8.4
	Q	最大	1.01	1.21	1.42	1.42	1.43	1.93	2.33	2.73	2.93	3.26	4.96
			0.65	0.85	1.05	1.05	0.91	1.40	1.79	2.19	2.38	2.70	4.36
	十字穴の番号	1				2				3			
r	最大	0.3				0.4		0.5		0.6		0.7	0.9
d	最大	2.1	2.4	2.6	2.7	3.1	3.65	4.15	4.65	5.2	6.2	8.2	
	最小	2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	8	
ねじの山数25.4mmに付き		32	32	28	28	24	18	16	14	12	10	9	

		2.0												
長さ	入り数	鉄												
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	GB (GALV)	亜鉛黒	真鍮めき	黒ツケル	ステンレス		
4	10000×18													●
4	10000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×18													●
5	10000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
6	10000×18													●
6	9000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	7000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	8000×18													●
10	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
10	6000×18													●
12	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
12	6000×18													●
14	4000×18													●
16	3000×18													●
16	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
20	3000×18													●

		2.3												
長さ	入り数	鉄												
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	GB (GALV)	亜鉛黒	真鍮めき	黒ツケル	ステンレス		
6	6000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
9	4000×20	●												●
10	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
14	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●

		2.5					
長さ	入り数	鉄					
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム
10	3000×20	●			●		●
12	2500×20	●	●	●	●	●	●
16	1800×20			●			

小ねじ
メソコねじ
組込みねじ
タップピンねじ
タツタイト
ハイエックねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップボルト
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト