

⊕ トラストッピンねじ(1種 A形)



20000003

20020003

20030003

20120003

20190003

20090003

鉄


ステンレス

SUS 410

SUS 316L

SUS ミラクル

チタン

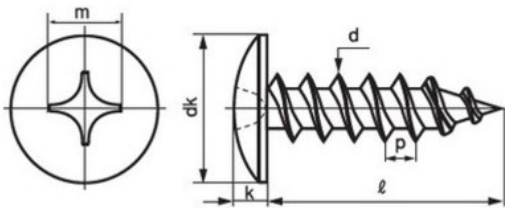

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	8	
dk	基準寸法	4.5	5.2	5.7	5.9	6.9	8.1	9.4	10.6	11.8	14.0	17.8	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	0 -0.8	
k	基準寸法	1.20	1.40	1.50	1.60	1.90	2.20	2.50	2.80	3.10	3.70	4.80	
	許容差	±0.1				±0.15				±0.2			
十字穴	m	参考	2.2	2.4	2.5	2.6	2.9	4.0	4.3	4.7	5.0	6.3	7.8
	Q	最大	1.01	1.21	1.32	1.42	1.72	1.83	2.13	2.53	2.83	2.86	4.36
		最小	0.65	0.85	0.95	1.05	1.34	1.30	1.60	1.99	2.29	2.31	3.78
		十字穴の番号	1				2				3		
r	最大	0.3				0.4		0.5		0.6	0.7	0.9	
d	最大	2.1	2.4	2.6	2.7	3.1	3.65	4.15	4.65	5.2	6.2	8.2	
	最小	2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	8	
ねじの山数25.4mmに付き		32	32	28	28	24	18	16	14	12	10	9	

2.0

長さ	入り数	鉄													ステンレス					
		コクロ	クロメイト	三層ホウダイト	三層ブラック	ニッケル	クロム	クロム	クロム	亜鉛黒	真鍮の黒	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	BK	
4	10000×24																			
5	7000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	8000×24																			
6	6000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	8000×24																			
8	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×24																			
10	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	5000×24																			
12	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

2.6

長さ	入り数	鉄													ステンレス					
		コクロ	クロメイト	三層ホウダイト	三層ブラック	ニッケル	クロム	クロム	クロム	亜鉛黒	真鍮の黒	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	BK	
5	5000×24																			
6	3500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	5000×24																			
8	3000×18																			
8	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×18																			
12	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	3000×18																			
16	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1200×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●