

⊕ ナベワッシャーヘッドタッピンねじ (1種 A形)




2000000W

2002000W

鉄

ステンレス

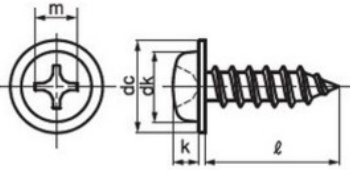

呼び径		3	3.5	4	5	
dk	基準寸法	5.5	6.0	7.0	9.0	
	許容差	0 -0.5		0 -0.6		
dc	基準寸法	8.0	9.0	10.0	12.0	
	許容差	0 -0.5				
k	基準寸法	2.2	2.5	3	3.5	
	許容差	±0.2		±0.3		
十字穴	m	参考	3.6	3.9	4.2	4.9
	Q	最大	1.43	1.73	2.03	2.73
		最小	0.86	1.15	1.45	2.14
十字穴の番号		2				
d	最大	3.1	3.65	4.15	5.2	
	最小	3	3.5	4	5	
ねじの山数25.4mmに付き		24	18	16	12	

2.0				
長さ	入り数	鉄		ステンレス
		クロメート	亜鉛黒	ステンレス
6	5000×20		●	
8	4000×20	●	●	
12	4000×16			●

2.6							
長さ	入り数	鉄					
		クロメート	三価ホワイト	三価ブラック	ニッケル	亜鉛黒	メッキ
6	2500×20	●	●	●	●	●	●
8	2500×20	●	●	●	●	●	●
10	2000×20	●	●	●	●	●	●
12	2000×20	●	●	●	●	●	●
16	1500×20	●	●	●	●	●	●
20	1200×20	●	●	●	●	●	●

3.0													
長さ	入り数	鉄									ステンレス		
		生地	クロメート	三価ホワイト	三価ブラック	ニッケル	クロム	G	亜鉛黒	メッキ	生地	ステンレス	
5	1800×20		●	●		●							
5	2000×18										●	●	●
6	1800×20	●	●	●	●	●	●	●	●	●			
6	2000×18										●	●	●
8	1500×20	●	●	●	●	●	●	●	●	●			
8	2000×18										●	●	●
10	1200×20		●	●	●	●	●	●	●	●			
10	2000×18										●	●	●
12	1800×14	●	●	●	●	●	●	●	●	●			
12	2000×18										●	●	●
14	1600×14	●	●	●	●	●	●	●	●	●			
16	1000×24										●	●	●
16	1500×14	●	●	●	●	●	●	●	●	●			
20	1000×14	●	●	●	●	●	●	●	●	●			
20	1000×18										●	●	●
25	800×14	●	●	●	●	●	●	●	●	●			
30	700×14	●	●	●	●	●	●	●	●	●			
35	600×14	●	●	●	●	●	●	●	●	●			

3.5					
長さ	入り数	鉄			ステンレス
		クロメート	三価ホワイト	三価ブラック	ステンレス
6	2000×14	●			
10	1800×14	●	●	●	●
13	1500×14	●	●	●	●
16	1200×14	●	●	●	●
20	900×14	●	●	●	●
25	700×14	●	●	●	●

4.5					
長さ	入り数	鉄			亜鉛黒
		クロメート	三価ホワイト	三価ブラック	亜鉛黒
12	600×14	●	●	●	●
13	500×14			●	●
16	500×14	●	●	●	●
20	400×14	●	●	●	●
30	400×10	●	●	●	●