

小ねじ
マフクロねじ
組込みねじ
タッピンねじ
タフタイト・ハイエックねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

4.0													
長さ	入り数	鉄										ステンレス	
		生地	クロム	クロム	三層クロム	三層クロム	ニッケル	クロム	クロム	クロム	クロム	生地	クロム
8	1200×14	●	●	●	●	●	●	●	●	●	●		
10	1000×14	●	●	●	●	●	●	●	●	●	●		
10	1000×18											●	●
12	1000×14		●	●	●	●	●	●	●	●	●		
12	1000×18											●	●
13	1000×14	●	●	●	●	●	●	●	●	●	●		
14	800×14	●	●	●	●	●	●	●	●	●	●		
15	800×14	●	●	●	●	●	●	●	●	●	●		
16	500×24											●	●
16	800×14	●	●	●	●	●	●	●	●	●	●		
18	700×14	●	●	●	●	●	●	●	●	●	●		
20	500×24											●	●
20	700×14	●	●	●	●	●	●	●	●	●	●		
25	500×18	●	●	●	●	●	●	●	●	●	●		
25	500×14	●	●	●	●	●	●	●	●	●	●		
30	400×14	●	●	●	●	●	●	●	●	●	●		
30	500×14											●	●
32	350×14	●	●	●	●	●	●	●	●	●	●		
35	200×24											●	●
35	350×14	●	●	●	●	●	●	●	●	●	●		
40	200×24											●	●
40	500×10	●	●	●	●	●	●	●	●	●	●		
50	200×18											●	●
50	400×10	●	●	●	●	●	●	●	●	●	●		
60	250×10	●	●	●	●	●	●	●	●	●	●		
65	250×10	●	●	●	●	●	●	●	●	●	●		
70	250×10	●	●	●	●	●	●	●	●	●	●		
75	250×10	●											

5.0													
長さ	入り数	鉄										ステンレス	
		生地	クロム	クロム	三層クロム	三層クロム	ニッケル	クロム	クロム	クロム	クロム	生地	クロム
10	600×14	●	●	●	●	●	●	●	●	●	●		
12	500×14	●	●	●	●	●	●	●	●	●	●		
16	500×14	●	●	●	●	●	●	●	●	●	●		
16	500×18											●	●
20	200×24											●	●
20	450×14	●	●	●	●	●	●	●	●	●	●		
25	200×24											●	●
25	500×10	●	●	●	●	●	●	●	●	●	●		
30	200×18											●	●
30	500×10	●	●	●	●	●	●	●	●	●	●		
35	200×18											●	●
35	400×10	●	●	●	●	●	●	●	●	●	●		
40	100×24											●	●
40	350×10	●	●	●	●	●	●	●	●	●	●		
45	100×24											●	●
45	300×10	●	●	●	●	●	●	●	●	●	●		
50	100×24											●	●
50	250×10	●	●	●	●	●	●	●	●	●	●		
55	100×24											●	●
60	100×24											●	●

⊕ 六角アプセットタッピンねじ(1種 A形)




2000000A

鉄

2002000A

ステンレス

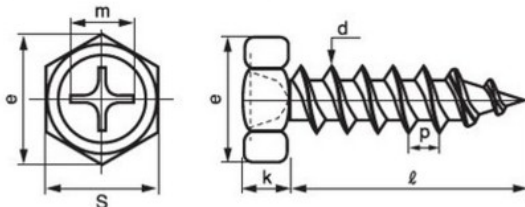

呼び径		4	5	6	7	8	
二面幅 (S)	基準寸法	7.0	8.0	10.0		12.0	
	許容差	0 -0.2				0 -0.25	
e	最小	7.7	8.7	10.9		13.1	
高さ (k)	基準寸法	2.5	3.0	3.5	4.2	5.0	
	許容差	±0.1		±0.15			
十字穴	m	4.1	4.5	6.3		7.3	
	Q	最大	1.93	2.33	2.86		3.86
		最小	1.40	1.80	2.30		3.20
	十字穴の番号		2		3		
d	最大	4.15	5.2	6.2	7.2	8.2	
	最小	4	5	6	7	8	
ねじの山数25.4mmに付き		16	12	10	10	9	