


8.0												
長さ	入り数	鉄										ステンレス (SUS304)
		コクロ シート	三 重 ホ ウ ア イ ト	三 重 フ ラ ン ジ	ニ ツ ゲ ル	ク ロ ム	亜 鉛 黒	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	
15	200×14	●	●	●	●	●	●	●	●	●	●	●
16	100×24											●
20	100×24											●
20	180×14	●	●	●	●	●	●	●	●	●	●	●
25	100×24											●
25	250×10	●	●	●	●	●	●	●	●	●	●	●
30	100×18											●
30	200×10	●	●	●	●	●	●	●	●	●	●	●
35	100×18											●
35	170×10	●	●	●	●	●	●	●	●	●	●	●
40	150×10	●	●	●	●	●	●	●	●	●	●	●
40	50×24											●
45	130×10	●	●	●	●	●	●	●	●	●	●	●
45	50×24											●
50	120×10	●	●	●	●	●	●	●	●	●	●	●
50	50×24											●
55	50×24											●
60	100×10	●	●			●						●
60	50×18											●
65	50×18											●
70	50×18											●
75	100×10	●										●
75	50×18											●
80	50×14											●

⊕ ⊖ 六角フランジタッピンねじ(1種 A形)



2000020B 鉄
2002020B ステンレス

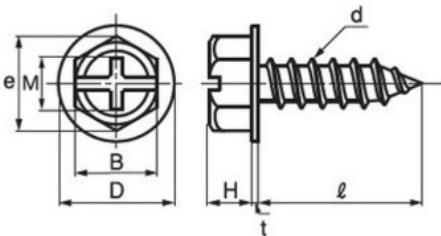

ねじの呼び径	B		D		H		T		参考	e	d	
	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差	基準寸法	許容差			最小	最大
M4	7	0	9	±0.4	2.5	±0.3	0.6	±0.15	4	7.7	4.15	4
M5	8	-0.2	10	±0.4	3	±0.3	0.8	±0.15	4.4	8.7	5.2	5
M6	10	0	13	±0.5	4	±0.5	1.2	±0.2	6.2	10.9	6.2	6
M8	12	-0.25	16	±0.5	5	±0.5	1.2	±0.2	7.2	13.1	8.2	8

4.0												
長さ	入り数	鉄										ステンレス
		コクロ シート	三 重 ホ ウ ア イ ト	三 重 フ ラ ン ジ	ニ ツ ゲ ル	亜 鉛 黒	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	
8	1300×14	●	●	●	●	●	●	●	●	●	●	●
10	1200×14	●	●	●	●	●	●	●	●	●	●	●
12	1000×14	●	●	●	●	●	●	●	●	●	●	●
12	500×24											●
16	500×18											●
16	800×14	●	●	●	●	●	●	●	●	●	●	●
20	500×18											●
20	600×14	●	●	●	●	●	●	●	●	●	●	●
25	200×24											●
25	500×14	●	●	●	●	●	●	●	●	●	●	●
50	400×10	●										●

5.0												
長さ	入り数	鉄										ステンレス
		コクロ シート	三 重 ホ ウ ア イ ト	三 重 フ ラ ン ジ	ニ ツ ゲ ル	亜 鉛 黒	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	メ ン ブ ラ ン	
10	800×14	●	●	●	●	●	●	●	●	●	●	●
12	500×14											●
12	600×14	●	●	●	●	●	●	●	●	●	●	●
16	500×14	●	●	●	●	●	●	●	●	●	●	●
20	200×24											●
20	450×14	●	●	●	●	●	●	●	●	●	●	●
25	200×24											●
25	600×10	●	●	●	●	●	●	●	●	●	●	●
30	200×18											●
40	300×10	●	●									●

小ねじ
メソクロねじ
組込みねじ
タッピンねじ
タツタイト
ハイエタねじ
いたすら防止ねじ
建材用スクリーン
ボルト
キャップホロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト