

# ステンレス ⊕ ナベタッピンねじ(1種 A形) 輸入品


2002U000  
ステンレス

呼び	入り数	生地
4×10	20000×1	●
4×12	18000×1	●
4×16	1000×12	●
4×20	500×24	●

# ⊕ ナベタッピンねじ(2種溝付き B-1形)



21000000 鉄  
21020000 ステンレス  
21030000 SUS 410  
21120000 SUS 316L  
21090000 チタン

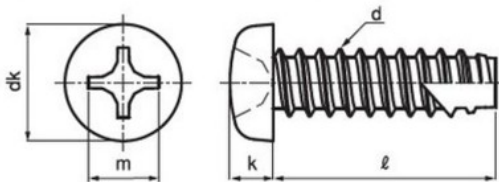

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	3.5	4.0	4.5	4.5	5.5	6.0	7.0	8.0	9.0	10.5	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	
k	基準寸法	1.3	1.5	1.7	1.7	2.0	2.3	2.6	2.9	3.3	3.9	
	許容差	±0.1				±0.15				±0.2		
十字穴	m	参考	2.2	2.4	2.6	2.6	3.6	3.9	4.2	4.6	4.9	6.3
	Q	最大	1.01	1.21	1.42	1.42	1.43	1.73	2.03	2.43	2.73	2.86
		最小	0.60	0.80	1.00	1.00	0.86	1.15	1.45	1.84	2.14	2.26
	十字穴の番号		1				2				3	
d	最大	2.00	2.30	2.50	2.60	3.00	3.50	4.00	4.50	5.00	6.00	
	最小	1.90	2.20	2.40	2.50	2.90	3.40	3.85	4.35	4.85	5.85	
ねじの山数25.4mmに付き		40	32	28	28	24	20	18	16	16	14	

長さ	入り数	2.0												
		コクロ	クロメイト	三価ホウソウ	ラケル	クロム	亜鉛黒	黒ラケル	三価ホウソウ	クロム	クロムS	クロムS	クロムS	ステンレス
3	12000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
4	10000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
4	10000×24	●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×18													●
5	8000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
6	10000×18													●
6	8000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	6000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	8000×18													●
10	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
10	6000×18													●
12	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
12	6000×18													●
14	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
18	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●
20	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1500×20				●		●	●	●	●	●	●	●	●

長さ	入り数	2.3												
		生地	コクロ	クロメイト	三価ホウソウ	ラケル	クロム	亜鉛黒	黒ラケル	三価ホウソウ	クロム	クロムS	クロムS	クロムS
4	7000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
5	6000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
6	6000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
10	4000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●
14	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●
18	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1500×20	●	●	●	●	●	●	●	●	●	●	●	●	●

小ねじ  
マフロねじ  
組込みねじ  
タッピンねじ  
ハイテックねじ  
ツラタイト  
いたすら防止ねじ  
建材用スクリーン  
ボルト  
キャップボルト  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト