


# ⊕ 盤タッピンねじ(2種溝付き B-1形)



21000001	21020001	21030001	21090001
鉄	ステンレス	SUS 410	チタン

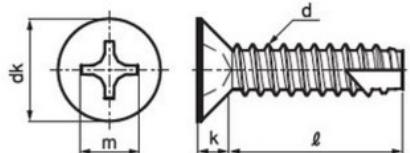

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0
	許容差	0 -0.4				0 -0.5				0 -0.6	0 -0.7
k	基準寸法	1.20	1.35	1.45	1.50	1.75	2.00	2.30	2.55	2.80	3.40
	許容差	0 -0.2				0 -0.3				0 -0.4	
十字穴	m 参考	2.2	2.4	2.6	2.6	3.6	4.1	4.5	4.9	5.1	6.7
	最大	1.01	1.21	1.42	1.42	1.43	1.93	2.33	2.73	2.93	3.26
	最小	0.65	0.85	1.05	1.05	0.91	1.40	1.79	2.19	2.38	2.70
十字穴の番号		1				2				3	
d	最大	2.00	2.30	2.50	2.60	3.00	3.50	4.00	4.50	5.00	6.00
	最大	1.90	2.20	2.40	2.50	2.90	3.40	3.85	4.35	4.85	5.85
ねじの山数25.4mmに付き		40	32	28	28	24	20	18	16	16	14

2.0											
長さ	入り数	ヨドコロ	クロスメート	三種ボーリング	三種フランジ	ラゲル	クローム	黒	黒ラゲル	三種ボーリング	三種フランジ
4	12000×20	●	●	●	●	●	●	●	●	●	●
5	10000×20	●	●	●	●	●	●	●	●	●	●
5	10000×24									●	
6	10000×18									●	
6	9000×20	●	●	●	●	●	●	●	●	●	●
8	7000×20	●	●	●	●	●	●	●	●	●	●
8	8000×18									●	
10	5000×20	●	●	●	●	●	●	●	●	●	●
10	6000×18									●	
12	4000×20	●	●	●	●	●	●	●	●	●	●
12	6000×18									●	
14	3500×20	●	●	●	●	●	●	●	●	●	●
16	2500×20	●	●	●	●	●	●	●	●	●	●

2.3											
長さ	入り数	ヨドコロ	クロスメート	三種ボーリング	三種フランジ	ラゲル	クローム	黒	黒ラゲル	三種ボーリング	三種フランジ
6	6000×20	●	●	●	●	●	●	●	●	●	●
8	5000×20	●	●	●	●	●	●	●	●	●	●
10	4000×20	●	●	●	●	●	●	●	●	●	●
12	3000×20	●	●	●	●	●	●	●	●	●	●
14	2200×20	●	●	●	●	●	●	●	●	●	●
16	2000×20	●	●	●	●	●	●	●	●	●	●
18	2000×20	●	●	●	●	●	●	●	●	●	●
20	1500×20	●	●	●	●	●	●	●	●	●	●
25	1000×20								●		

2.5											
長さ	入り数	ヨドコロ	クロスメート	三種ボーリング	三種フランジ	ニッケル	クローム	黒	黒ラゲル	三種ボーリング	三種フランジ
6	5000×20	●	●	●	●	●	●	●	●	●	●
8	4000×20	●	●	●	●	●	●	●	●	●	●
10	3000×20	●	●	●	●	●	●	●	●	●	●
12	2500×20	●	●	●	●	●	●	●	●	●	●

2.6											
長さ	入り数	生地	ヨドコロ	クロスメート	三種ボーリング	三種フランジ	ニッケル	クローム	黒	黒ラゲル	三種ボーリング
5	5000×20	●	●	●	●	●	●	●	●	●	●
6	5000×20	●	●	●	●	●	●	●	●	●	●
6	6000×18										●
8	4000×20	●	●	●	●	●	●	●	●	●	●
8	6000×18										●
10	3000×20	●	●	●	●	●	●	●	●	●	●
10	4000×18										●
12	2500×20	●	●	●	●	●	●	●	●	●	●
12	3000×18										●
14	2000×20	●	●	●	●	●	●	●	●	●	●
16	1800×20	●	●	●	●	●	●	●	●	●	●
16	3000×18										●
18	1600×20	●	●	●	●	●	●	●	●	●	●
20	1500×20	●	●	●	●	●	●	●	●	●	●

小ねじ

マイクロねじ

ハイドロクねじ

いたずら防止ねじ

建材用スクリュー

ボルト

キャップ・ナット

座金

つまみねじ

ナット

樹脂製品

アンカーボルト