

5.0																
長さ	入り数	鉄														ステンレス
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	生地
10	1100×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	500×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	500×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	500×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
18	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×18	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	500×18	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	200×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	200×24	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	200×18	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
50	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
90	250×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

6.0																
長さ	入り数	鉄														ステンレス
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	生地
12	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	400×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

⊕ 丸皿タップピンねじ(2種溝付き B-1 形)




21000002

鉄

21020002

ステンレス

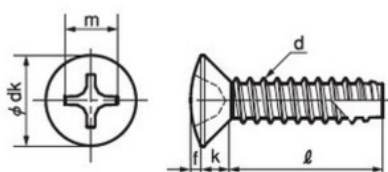

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	
k+f	基準寸法	1.60	1.85	2.00	2.10	2.45	2.80	3.20	3.55	4.00	4.80	
	許容差	0 -0.4				0 -0.5					0 -0.6	
十字穴	m	参考	2.4	2.7	2.9	2.9	3.8	4.3	4.7	5.1	5.3	6.9
	Q	最大	1.21	1.52	1.72	1.72	1.63	2.13	2.53	2.93	3.13	3.46
		最小	0.85	1.14	1.34	1.34	1.11	1.60	1.99	2.38	2.58	2.90
	十字穴の番号		1				2					3
d	最大	2.00	2.30	2.50	2.60	3.00	3.50	4.00	4.50	5.00	6.00	
	最小	1.90	2.20	2.40	2.50	2.90	3.40	3.85	4.35	4.85	5.85	
ねじの山数25.4mmに付き		40	32	28	28	24	20	18	16	16	14	

2.0																
長さ	入り数	鉄														ステンレス
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	生地
10	5000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

2.6																
長さ	入り数	鉄														ステンレス
		クロメート	クロメート	三価ホウ酸	三価ホウ酸	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	生地
6	4500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	3500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1800×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●