

⊕ 丸皿タッピンねじ(2種溝付き B-1形)

		3.0													ステンレス	
長さ	入り数	鉄													生地	
		コクロ	クロニート	三層ホワイト	三層ブラック	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム		
6	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	3000×24															●
8	2000×24															●
8	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×24															●
12	2000×24															●
12	2500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	2200×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1200×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

		3.5														
長さ	入り数	鉄														
		生地	コクロ	クロニート	三層ホワイト	三層ブラック	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム		
8	2500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2500×14															●
12	2000×14															●
16	1600×14															●
20	1000×14															●
25	1000×14															●


		4.0													ステンレス	
長さ	入り数	鉄													生地	
		コクロ	クロニート	三層ホワイト	三層ブラック	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム		
8	2000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×18															●
10	1000×24															●
10	1600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×24															●
12	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	1000×18															●
14	1200×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
15	1200×14															●
16	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1000×18															●
20	500×24															●
20	900×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

		5.0														
長さ	入り数	鉄														
		コクロ	クロニート	三層ホワイト	三層ブラック	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム		
10	900×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	800×14															●
15	700×14															●
16	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

⊕ トラストタッピンねじ(2種溝付き B-1形)



21000003	21020003	21030003	21120003
鉄	ステンレス	SUS 410	SUS 316L

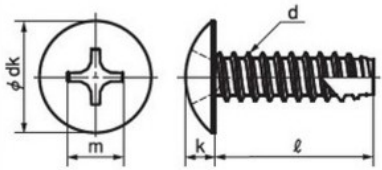

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	4.5	5.2	5.7	5.9	6.9	8.1	9.4	10.6	11.8	14.0	
	許容差	0 -0.4					0 -0.5			0 -0.6		0 -0.7
k	基準寸法	1.20	1.40	1.50	1.60	1.90	2.20	2.50	2.80	3.10	3.70	
	許容差	±0.1					±0.15					±0.2
十字穴	m	参考	2.2	2.4	2.5	2.6	2.9	4.0	4.3	4.7	5.0	6.3
	Q	最大	1.01	1.21	1.32	1.42	1.72	1.83	2.13	2.53	2.83	2.86
		最小	0.65	0.85	0.95	1.05	1.34	1.30	1.60	1.99	2.29	2.31
十字穴の番号		1					2					3
d	最大	2.00	2.30	2.50	2.60	3.00	3.50	4.00	4.50	5.00	6.00	
	最小	1.90	2.20	2.40	2.50	2.90	3.40	3.85	4.35	4.85	5.85	
ねじの山数25.4mmに付き		40	32	28	28	24	20	18	16	16	14	