

⊕ ナベワッシャーヘッドタッピンねじ(2種溝付 B-1形)

3.0		鉄									
長さ	入り数	鉄									
		コテロ	クロメート	三徳ホワイト	三徳ブラック	ニッケル	クローム	亜鉛黒	メッキ	メッキ	メッキ
5	1800×20	●	●	●	●	●	●	●	●	●	●
6	1800×20	●	●	●	●	●	●	●	●	●	●
7	1600×20	●	●	●	●	●	●	●	●	●	●
8	1500×20	●	●	●	●	●	●	●	●	●	●
10	1200×20	●	●	●	●	●	●	●	●	●	●
12	1800×14	●	●	●	●	●	●	●	●	●	●
14	1500×14	●	●	●	●	●	●	●	●	●	●
16	1500×14	●	●	●	●	●	●	●	●	●	●
18	1200×14	●	●	●	●	●	●	●	●	●	●
20	1000×14	●	●	●	●	●	●	●	●	●	●
22	900×14	●	●	●	●	●	●	●	●	●	●
25	900×14	●	●	●	●	●	●	●	●	●	●

4.0		鉄										ステンレス	
長さ	入り数	鉄										生地	ステンレス
		コテロ	クロメート	三徳ホワイト	三徳ブラック	ニッケル	クローム	亜鉛黒	メッキ	メッキ	メッキ		
8	1000×18	●	●	●	●	●	●	●	●	●	●	●	●
8	1200×14	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×14	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×18	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×14	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×18	●	●	●	●	●	●	●	●	●	●	●	●
14	800×14	●	●	●	●	●	●	●	●	●	●	●	●
16	800×14	●	●	●	●	●	●	●	●	●	●	●	●
18	700×14	●	●	●	●	●	●	●	●	●	●	●	●
20	700×14	●	●	●	●	●	●	●	●	●	●	●	●
25	500×14	●	●	●	●	●	●	●	●	●	●	●	●

5.0		鉄											
長さ	入り数	鉄											
		コテロ	クロメート	三徳ホワイト	三徳ブラック	ニッケル	クローム	亜鉛黒	メッキ	メッキ	メッキ	メッキ	
8	700×14	●	●	●	●	●	●	●	●	●	●	●	●
10	700×14	●	●	●	●	●	●	●	●	●	●	●	●
12	600×14	●	●	●	●	●	●	●	●	●	●	●	●
16	500×14	●	●	●	●	●	●	●	●	●	●	●	●
20	400×14	●	●	●	●	●	●	●	●	●	●	●	●

鉄 ⊕ 六角アプセットタッピンねじ (2種溝付きB-1形)



2100000A

鉄

5.0		鉄					
長さ	入り数	鉄					
		コテロ	クロメート	三徳ホワイト	三徳ブラック	ニッケル	亜鉛黒
12	800×14	●	●	●	●	●	●
14	700×14	●	●	●	●	●	●
16	600×14	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●
22	800×10	●	●	●	●	●	●

6.0		鉄					
長さ	入り数	鉄					
		コテロ	クロメート	三徳ホワイト	三徳ブラック	ニッケル	亜鉛黒
12	500×14	●	●	●	●	●	●
14	400×14	●	●	●	●	●	●

⊕ ナベタッピンねじ(2種溝なし B-0形)



21000100

鉄

21020100


ステンレス

21030100

SUS 410

21090100

チタン

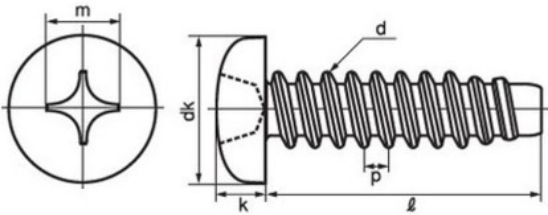

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	3.5	4.0	4.5	4.5	5.5	6.0	7.0	8.0	9.0	10.5	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	
k	基準寸法	1.3	1.5	1.7	1.7	2.0	2.3	2.6	2.9	3.3	3.9	
	許容差	±0.1				±0.15				±0.2		
十字穴	m	2.2	2.4	2.6	2.6	3.6	3.9	4.2	4.6	4.9	6.3	
	Q	最大	1.01	1.21	1.42	1.42	1.43	1.73	2.03	2.43	2.73	2.86
		最小	0.60	0.80	1.00	1.00	0.86	1.15	1.45	1.84	2.14	2.26
	十字穴の番号		1				2				3	
d	最大	2.00	2.30	2.50	2.60	3.00	3.50	4.00	4.50	5.00	6.00	
	最小	1.90	2.20	2.40	2.50	2.90	3.40	3.85	4.35	4.85	5.85	
ねじの山数25.4mmに付き		40	32	28	28	24	20	18	16	16	14	