

# ⊕ 皿タッピンねじ (2種溝なし B-0形)



21000101

鉄

21020101


ステンレス

21030101

SUS 410

21090101

チタン

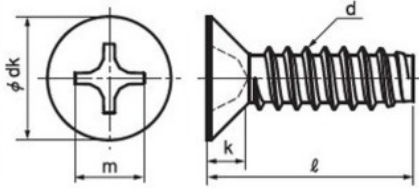

| 呼び径            |        | 2         | 2.3  | 2.5  | 2.6  | 3         | 3.5  | 4    | 4.5       | 5    | 6         |
|----------------|--------|-----------|------|------|------|-----------|------|------|-----------|------|-----------|
| dk             | 基準寸法   | 4.0       | 4.6  | 5.0  | 5.2  | 6.0       | 7.0  | 8.0  | 9.0       | 10.0 | 12.0      |
|                | 許容差    | 0<br>-0.4 |      |      |      | 0<br>-0.5 |      |      | 0<br>-0.6 |      | 0<br>-0.7 |
| k              | 基準寸法   | 1.20      | 1.35 | 1.45 | 1.50 | 1.75      | 2.00 | 2.30 | 2.55      | 2.80 | 3.40      |
|                | 許容差    | 0<br>-0.2 |      |      |      | 0<br>-0.3 |      |      | 0<br>-0.4 |      | 0<br>-0.4 |
| 十字穴            | m      | 参考        | 2.2  | 2.4  | 2.6  | 2.6       | 3.6  | 4.1  | 4.5       | 4.9  | 5.1       |
|                | Q      | 最大        | 1.01 | 1.21 | 1.42 | 1.42      | 1.43 | 1.93 | 2.33      | 2.73 | 3.26      |
|                | 最小     | 0.65      | 0.85 | 1.05 | 1.05 | 0.91      | 1.40 | 1.79 | 2.19      | 2.38 | 2.70      |
|                | 十字穴の番号 | 1         |      |      |      | 2         |      |      |           | 3    |           |
| d              | 最大     | 2.0       | 2.3  | 2.5  | 2.6  | 3.0       | 3.5  | 4.0  | 4.5       | 5.0  | 6.0       |
|                | 最小     | 1.90      | 2.20 | 2.40 | 2.50 | 2.90      | 3.40 | 3.85 | 4.35      | 4.85 | 5.85      |
| ねじの山数25.4mmに付き |        | 40        | 32   | 28   | 28   | 24        | 20   | 18   | 16        | 16   | 14        |

| 2.0 |          | 鉄  |       |       |        |        |      |     |     |     |        |        |     |     |     | ステンレス |       |
|-----|----------|----|-------|-------|--------|--------|------|-----|-----|-----|--------|--------|-----|-----|-----|-------|-------|
| 長さ  | 入り数      | 生地 | クロメート | クロメート | 三価ホワイト | 三価ブラック | ニッケル | クロム | 亜鉛黒 | 黒ツヤ | 三価ホワイト | 三価ブラック | クロム | 亜鉛黒 | 黒ツヤ | 生地    | ステンレス |
| 4   | 10000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 4   | 12000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 5   | 10000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 5   | 10000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 6   | 10000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 6   | 9000×20  | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 8   | 7000×20  | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 8   | 8000×16  |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 10  | 5000×20  | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 10  | 6000×16  |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 12  | 4000×20  | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 12  | 6000×16  |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 14  | 3500×20  | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 14  | 4000×16  |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 16  | 2500×20  |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 16  | 3000×16  |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |

| 2.3 |         | 鉄  |       |       |        |        |      |     |     |     |        |        |     |     |     | ステンレス |       |
|-----|---------|----|-------|-------|--------|--------|------|-----|-----|-----|--------|--------|-----|-----|-----|-------|-------|
| 長さ  | 入り数     | 生地 | クロメート | クロメート | 三価ホワイト | 三価ブラック | ニッケル | クロム | 亜鉛黒 | 黒ツヤ | 三価ホワイト | 三価ブラック | クロム | 亜鉛黒 | 黒ツヤ | 生地    | ステンレス |
| 5   | 7000×20 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 6   | 6000×20 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 8   | 5000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 10  | 4000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 12  | 3000×20 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 14  | 2200×20 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 16  | 2000×20 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 18  | 2000×20 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 20  | 1500×20 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |

| 2.5 |         | 鉄  |       |       |        |        |      |     |     |     |        |        |     |     |     | ステンレス |       |
|-----|---------|----|-------|-------|--------|--------|------|-----|-----|-----|--------|--------|-----|-----|-----|-------|-------|
| 長さ  | 入り数     | 生地 | クロメート | クロメート | 三価ホワイト | 三価ブラック | ニッケル | クロム | 亜鉛黒 | 黒ツヤ | 三価ホワイト | 三価ブラック | クロム | 亜鉛黒 | 黒ツヤ | 生地    | ステンレス |
| 6   | 5000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 8   | 4000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 10  | 3000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 12  | 2500×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |

| 2.6 |         | 鉄  |       |       |        |        |      |     |     |     |        |        |     |     |     | ステンレス |       |
|-----|---------|----|-------|-------|--------|--------|------|-----|-----|-----|--------|--------|-----|-----|-----|-------|-------|
| 長さ  | 入り数     | 生地 | クロメート | クロメート | 三価ホワイト | 三価ブラック | ニッケル | クロム | 亜鉛黒 | 黒ツヤ | 三価ホワイト | 三価ブラック | クロム | 亜鉛黒 | 黒ツヤ | 生地    | ステンレス |
| 5   | 5000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 5   | 8000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 6   | 5000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 6   | 6000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 8   | 4000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 8   | 6000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 10  | 3000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 10  | 4000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 12  | 2500×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 12  | 3000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 14  | 2000×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 16  | 1800×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 16  | 2000×16 |    |       |       |        |        |      |     |     |     |        |        |     |     |     | ●     | ●     |
| 18  | 1600×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |
| 20  | 1500×20 | ●  | ●     | ●     | ●      | ●      | ●    | ●   | ●   | ●   | ●      | ●      | ●   | ●   | ●   | ●     | ●     |