


⊕ バインドタッピンねじ(2種溝なし B-0形)

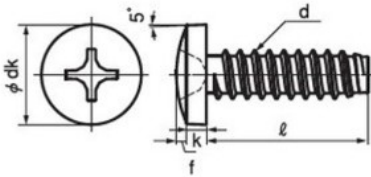

小ねじ
マフクロねじ
組込みねじ
タッピンねじ
タツタイト
ハイエタねじ
いたすら防止ねじ
建材用スクリュー
ボルト
キャップ・ロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

21000104 鉄	21020104 ステンレス	21030104 SUS 410
---------------	-------------------	---------------------



呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	4.3	4.9	5.3	5.5	6.3	7.3	8.3	9.3	10.3	12.4	
	許容差	0 -0.4			0 -0.5			0 -0.6			0 -0.7	
k+f	基準寸法	1.20	1.40	1.50	1.60	1.90	2.20	2.50	2.80	3.10	3.70	
	許容差	±0.15					±0.2					
十字穴	m	参考	2.2	2.4	2.5	2.6	3.7	4.0	4.3	4.7	5.0	6.3
	Q	最大	1.01	1.21	1.32	1.42	1.53	1.83	2.13	2.53	2.83	2.86
		最小	0.65	0.85	0.95	1.05	1.01	1.30	1.60	1.99	2.29	2.31
	十字穴の番号		1					2				
d	最大	2.00	2.30	2.50	2.60	3.00	3.50	4.00	4.50	5.00	6.00	
	最小	1.90	2.20	2.40	2.50	2.90	3.40	3.85	4.35	4.85	5.85	
ねじの山数 25.4mmに付き		40	32	28	28	24	20	18	16	16	14	

		2.0												ステンレス	
長さ	入り数	鉄												ステンレス	
		生地	クロロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ニッケル	三価ホウ酸	三価フッ素	ニッケル		クロム
3	10000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●
4	10000×18														●
4	8000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
5	10000×18														●
5	7000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
6	7000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
6	8000×18														●
8	5000×18														●
8	5000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
10	4000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
10	5000×18														●
12	3500×20				●	●				●	●	●	●	●	●
12	5000×18														●

		2.3	
長さ	入り数	鉄	
		クロメート	三価ホウ酸
4	6000×20	●	●
5	5000×20		●
6	5000×20		●
8	4000×20		●
10	3000×20		●

		2.6												ステンレス	
長さ	入り数	鉄												ステンレス	
		生地	クロロ	クロメート	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ニッケル	三価ホウ酸	三価フッ素	ニッケル		クロム
4	4000×18														●
4	4000×20														●
5	4000×18														●
5	4000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
6	3500×20		●	●	●	●	●	●	●	●	●	●	●	●	●
6	5000×18														●
8	3000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
8	5000×18														●
10	2500×20		●	●	●	●	●	●	●	●	●	●	●	●	●
10	3000×18														●
12	2000×20		●	●	●	●	●	●	●	●	●	●	●	●	●
14	1800×20														●
16	1500×20														●
18	1500×20		●	●	●	●	●	●	●	●	●	●	●	●	●
20	1200×20		●	●						●	●				●