

⊕ ナベタップピンねじ(3種溝付き C-1形)

		5.0																
長さ	入り数	鉄												ステンレス				
		生地	クロメート	三価クロム	三価クロム	ニッケル	クロム	(A)クロム	亜鉛	銅	アルミニウム	ニッケル	クロム	ニッケル	銅	(A)クロム	(A)クロム	ω-Cr
6	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
8	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
8	1000×18																	
10	500×24																	
10	900×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
12	500×24																	
12	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
14	500×24																	
14	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
15	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
16	500×18																	
16	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
20	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
20	500×18																	
25	400×18																	
25	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
30	200×24																	
30	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
35	200×24																	
35	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
40	200×18																	
40	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
45	350×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
50	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●				


		6.0																
長さ	入り数	鉄												ステンレス				
		生地	クロメート	三価クロム	三価クロム	ニッケル	クロム	(A)クロム	亜鉛	銅	アルミニウム	ニッケル	クロム	(A)クロム	(A)クロム	ω-Cr		
10	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
12	500×18																	
12	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
14	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
14	500×18																	
15	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
16	200×24																	
16	450×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
18	200×24																	
20	200×24																	
20	350×14	●	●	●	●	●	●	●	●	●	●	●	●	●				
25	200×24																	
25	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
30	200×18																	
30	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
35	200×18																	
35	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
40	100×24																	
40	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
45	250×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
50	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
55	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●				
60	180×10																	
70	120×10																	
150	130×8																	
170	90×10																	

		8.0			
長さ	入り数	鉄			ステンレス
		クロメート	三価クロム	三価クロム	
30	200×10	●	●	●	●

⊕ 皿タップピンねじ(3種溝付き C-1形)



22000001	22020001
鉄	ステンレス

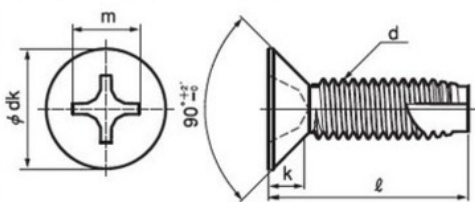

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	8	
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0	16.0	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7		0 -0.8
k	基準寸法	1.20	1.35	1.45	1.50	1.75	2.00	2.30	2.55	2.80	3.40	4.40	
	許容差	0 -0.2				0 -0.3			0 -0.4				
十字穴	m	参考	2.2	2.4	2.6	2.6	3.6	4.1	4.5	4.9	5.1	6.7	8.4
	Q	最大	1.01	1.21	1.42	1.42	1.43	1.93	2.33	2.73	2.93	3.26	4.96
	Q	最小	0.65	0.85	1.05	1.05	0.91	1.40	1.79	2.19	2.38	2.70	4.36
	十字穴の番号	1					2					3	
d	最大	1.98	2.28	2.48	2.58	2.98	3.47	3.97	4.47	4.97	5.97	7.96	
	最小	1.89	2.19	2.38	2.48	2.87	3.36	3.84	4.34	4.84	5.82	7.79	
P(ピッチ)		0.4	0.4	0.45	0.45	0.5	0.6	0.7	0.75	0.8	1.0	1.25	