

⊕ 皿タッピンねじ(3種溝付き C-1形)

		6.0																
長さ	入り数	鉄															ステンレス	
		生地	クロロ	クロメート	三層クロメート	三層クロメート	ニッケル	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	クロム	生地	クロメート
12	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
14	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
15	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
16	200×24																●	●
16	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
20	200×24																●	●
20	400×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
25	200×24																●	●
25	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
30	200×18																●	●
30	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
35	200×18																●	●
35	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
40	100×24																●	●
40	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
45	100×24																●	●
45	250×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
50	100×24																●	●
50	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
55	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
60	180×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
65	150×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
70	120×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
75	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
80	200×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
85	180×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
90	170×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
100	150×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		
110	130×10	●	●	●														
120	130×10	●	●	●														
130	120×10	●	●	●														
140	150×8	●	●	●														
150	140×8	●	●	●														
170	90×10	●	●	●														
180	80×10	●	●															
200	80×10	●	●															

		8.0			
長さ	入り数	鉄			
		クロロ	クロメート	三層クロメート	三層クロメート
20	200×14	●	●	●	●
25	220×10	●	●	●	●
30	200×10	●	●	●	●
35	180×10	●	●	●	●
40	160×10	●	●	●	●
45	150×10	●	●	●	●
50	130×10	●	●	●	●
55	120×10	●	●	●	●
60	100×10	●	●	●	●

⊕ 丸皿タッピンねじ(3種溝付き C-1形)




22000002

鉄

22020002

ステンレス

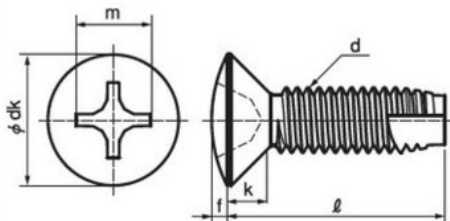

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7
k+f	基準寸法	1.60	1.85	2.00	2.10	2.45	2.80	3.20	3.55	4.00	4.80
	許容差	0 -0.4				0 -0.5					0 -0.6
十字穴	m	参考	2.4	2.7	2.9	2.9	3.8	4.3	4.7	5.1	5.3
	最大	1.21	1.52	1.72	1.72	1.63	2.13	2.53	2.93	3.13	3.46
	最小	0.85	1.14	1.34	1.34	1.11	1.60	1.99	2.38	2.58	2.90
	十字穴の番号	1				2					3
d	最大	1.98	2.28	2.48	2.58	2.98	3.47	3.978	4.47	4.976	5.97
	最小	1.89	2.19	2.38	2.48	2.874	3.36	3.838	4.34	4.826	5.82
P(ピッチ)		0.4	0.4	0.45	0.45	0.5	0.6	0.7	0.75	0.8	1.0