

⊕ 丸皿タッピンねじ(3種溝付き C-1形)

3.0		鉄														
長さ φdk	入り数	生地	丸皿	クロメート	三層ホワイト	三層ブラック	ニッケル	クローム	Zn	Ni	Al	Cu	P	S	その他	
																6
8	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	2500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	2000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1200×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

4.0		鉄														
長さ	入り数	丸皿	クロメート	三層ホワイト	三層ブラック	ニッケル	クローム	Zn	Ni	Al	Cu	P	S	その他		
															10	1600×14
12	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	900×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
45	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
50	450×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●


5.0		鉄														ステンレス	
長さ φdk	入り数	生地	丸皿	クロメート	三層ホワイト	三層ブラック	ニッケル	クローム	Zn	Ni	Al	Cu	P	S	その他		
																10	900×14
12	500×24																●
12	800×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
16	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	700×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	600×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
45	350×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
50	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

6.0		鉄															
長さ	入り数	丸皿	クロメート	三層ホワイト	三層ブラック	ニッケル	クローム	Zn	Ni	Al	Cu	P	S	その他			
															16	450×14	●
20	350×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
25	500×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
30	400×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
35	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
40	300×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
45	250×10	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●

⊕ トラストタッピンねじ(3種溝付き C-1形)



22000003	22020003
鉄	ステンレス

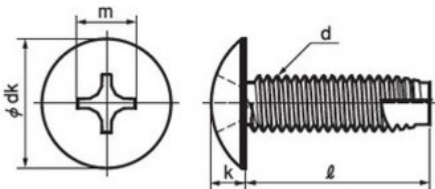

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	8	
dk	基準寸法	4.5	5.2	5.7	5.9	6.9	8.1	9.4	10.6	11.8	14.0	17.8	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	0 -0.8	
k	基準寸法	1.20	1.40	1.50	1.60	1.90	2.20	2.50	2.80	3.10	3.70	4.80	
	許容差	±0.1				±0.15				±0.2			
十字穴	m	参考	2.2	2.4	2.5	2.6	2.9	4.0	4.3	4.7	5.0	6.3	7.8
	Q	最大	1.01	1.21	1.32	1.42	1.72	1.83	2.13	2.53	2.83	2.86	4.36
	最小	0.65	0.85	0.95	1.05	1.34	1.30	1.60	1.99	2.29	2.31	3.78	
d	十字穴の番号	1					2				3		
	最大	1.98	2.28	2.48	2.58	2.98	3.47	3.97	4.47	4.97	5.97	7.96	
	最小	1.89	2.19	2.38	2.48	2.87	3.36	3.84	4.34	4.84	5.82	7.79	
P(ピッチ)		0.4	0.4	0.45	0.45	0.5	0.6	0.7	0.75	0.8	1.0	1.25	

小ねじ  
マフクロねじ  
組込みねじ  
タッピンねじ  
タツタイト  
ハイエックねじ  
いたすら防止ねじ  
建材用スクリーン  
ボルト  
キャップホーク  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト