


鉄 ⊕ 六角アプセットタッピンねじ (3種溝付き C-1形)



小ねじ
マフロねじ
組込みねじ
タッピンねじ
タツタイト
ハイテグねじ
いたすら防止ねじ
建材用スクリーナ
ボルト
キャップホーター
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト

2200000A

鉄

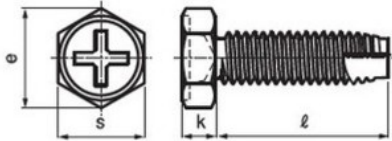

呼び径		4	5	6	8	
二面幅(S)	基準寸法	7.0	8.0	10.0	12.0	
	許容差	0 -0.2		0 -0.25		
e	最小	7.7	8.7	10.9	13.1	
	高さ(k)	基準寸法		基準寸法		
		2.5	3.0	3.5	5.0	
		許容差		許容差		
		±0.1		±0.15		
十字穴	m	参考	4.1	4.5	6.3	7.3
	Q	最大	1.93	2.33	2.86	3.86
		最小	1.40	1.80	2.30	3.20
	十字穴の番号		2		3	
d	最大	3.978	4.976	5.97	7.96	
	最小	3.838	4.826	5.82	7.79	
P(ピッチ)		0.7	0.8	1.0	1.25	

4.0											
長さ	入り数	コブラ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	EC	亜鉛黒	メッキ	メッキ
8	1600×14	●	●	●	●	●	●	●	●	●	●
10	1300×14	●	●	●	●	●	●	●	●	●	●
12	1200×14	●	●	●	●	●	●	●	●	●	●
16	1000×14	●	●	●	●	●	●	●	●	●	●

5.0											
長さ	入り数	生地	コブラ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	EC	亜鉛黒	メッキ
12	800×14	●	●	●	●	●	●	●	●	●	●
14	600×14	●	●	●	●	●	●	●	●	●	●
16	600×14	●	●	●	●	●	●	●	●	●	●
18	500×14	●	●	●	●	●	●	●	●	●	●
20	500×14	●	●	●	●	●	●	●	●	●	●

6.0											
長さ	入り数	コブラ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	EC	亜鉛黒	メッキ	メッキ
10	500×14	●	●	●	●	●	●	●	●	●	●
12	500×14	●	●	●	●	●	●	●	●	●	●
16	400×14	●	●	●	●	●	●	●	●	●	●
20	350×14	●	●	●	●	●	●	●	●	●	●
25	400×10	●	●	●	●	●	●	●	●	●	●
30	350×10	●	●	●	●	●	●	●	●	●	●
35	300×10	●	●	●	●	●	●	●	●	●	●
40	250×10	●	●	●	●	●	●	●	●	●	●
45	200×10	●	●	●	●	●	●	●	●	●	●


8.0											
長さ	入り数	コブラ	クロメート	三層ホワイト	三層ブラック	ニッケル	クロム	EC	亜鉛黒	メッキ	メッキ
16	200×14	●	●	●	●	●	●	●	●	●	●
20	180×14	●	●	●	●	●	●	●	●	●	●
25	250×10	●	●	●	●	●	●	●	●	●	●
30	200×10	●	●	●	●	●	●	●	●	●	●
35	170×10	●	●	●	●	●	●	●	●	●	●
40	150×10	●	●	●	●	●	●	●	●	●	●
45	130×10	●	●	●	●	●	●	●	●	●	●
50	120×10	●	●	●	●	●	●	●	●	●	●
60	100×10	●	●	●	●	●	●	●	●	●	●
70	80×10	●	●	●	●	●	●	●	●	●	●
80	50×10	●	●	●	●	●	●	●	●	●	●
100	50×10	●	●	●	●	●	●	●	●	●	●

鉄 TRX皿タッピンねじ(3種溝付き C-1形)



2200T001

鉄

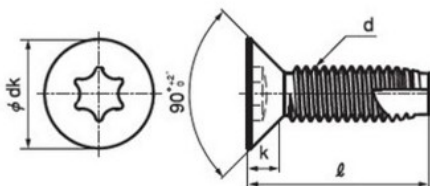

呼び径		5	6
dk	基準寸法	10.0	12.0
	許容差	0 -0.6	0 -0.7
k	基準寸法	2.80	3.40
	許容差	0 -0.3	0 -0.4
ドライブ サイズ	T型	T25	T30
d	最大	4.976	5.97
	最小	4.826	5.82
P(ピッチ)		0.8	1.0