


5.0						6.0						8.0					
長さ	入り数	コクロ	クロメート	三層クロメート	メッキ	長さ	入り数	コクロ	クロメート	三層クロメート	メッキ	長さ	入り数	コクロ	クロメート	三層クロメート	メッキ
16	700×14	●	●	●	●	16	500×14	●	●	●	●	30	200×10	●	●	●	●
20	600×14	●	●	●	●	20	400×14	●	●	●	●	35	180×10	●	●	●	●
25	700×10	●	●	●	●	25	500×10	●	●	●	●	40	160×10	●	●	●	●
30	600×10	●	●	●	●	30	400×10	●	●	●	●	45	150×10	●	●	●	●
35	500×10	●	●	●	●	35	300×10	●	●	●	●	50	130×10	●	●	●	●
40	400×10	●	●	●	●	40	300×10	●	●	●	●	55	120×10	●	●	●	●
50	300×10	●	●	●	●	45	250×10	●	●	●	●	60	100×10	●	●	●	●
						50	200×10	●	●	●	●	65	100×10	●	●	●	●
						55	200×10	●	●	●	●						
						60	180×10	●	●	●	●						
						65	150×10	●	●	●	●						
						70	120×10	●	●	●	●						
						75	200×10	●	●	●	●						
						80	200×10	●	●	●	●						
						85	180×10	●	●	●	●						
						90	170×10	●	●	●	●						
						100	150×10	●	●	●	●						

⊕ ナベタップピンねじ(3種溝なし C-0形)



22000100	22020100
鉄	ステンレス

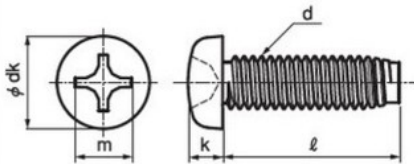

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	3.5	4.0	4.5	4.5	5.5	6.0	7.0	8.0	9.0	10.5	
	許容差	0 -0.4				0 -0.5			0 -0.6		0 -0.7	
k	基準寸法	1.3	1.5	1.7	1.7	2.0	2.3	2.6	2.9	3.3	3.9	
	許容差	±0.1				±0.15					±0.2	
十字穴	m	参考	2.2	2.4	2.6	2.6	3.6	3.9	4.2	4.6	4.9	6.3
	Q	最大	1.01	1.21	1.42	1.42	1.43	1.73	2.03	2.43	2.73	2.86
		最小	0.60	0.80	1.00	1.00	0.86	1.15	1.45	1.84	2.14	2.26
	十字穴の番号		1				2					3
d	最大	1.98	2.28	2.48	2.58	2.98	3.47	3.978	4.47	4.976	5.97	
	最小	1.89	2.19	2.38	2.48	2.874	3.36	3.838	4.34	4.826	5.82	
P(ピッチ)		0.4	0.4	0.45	0.45	0.5	0.6	0.7	0.75	0.8	1.0	

		M3.0																		
長さ	入り数	鉄														ステンレス				
		コクロ	クロメート	三層クロメート	メッキ	クロム	Q	B	G	亜鉛黒	亜鉛黒	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	ステンレス	
4	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
5	3000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	2500×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
6	3000×24																			●
8	2000×24																			●
8	2200×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×20	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×24																			●

		M4.0																		
長さ	入り数	鉄														ステンレス				
		コクロ	クロメート	三層クロメート	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	ステンレス	
6	2000×18																			●
8	1000×24																			●
8	2000×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1000×24																			●
10	1600×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×24																			●
12	1500×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	1000×18																			●
15	1000×18																			●
16	1000×18																			●
18	1000×15																			●
20	500×24																			●
25	500×24																			●
30	500×18																			●
35	500×18																			●
40	200×24																			●