


ステンレス ⊕ 丸皿タッピンねじ (3種溝なし C-0形)



22020102

ステンレス

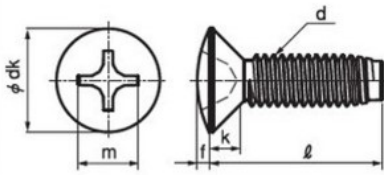

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	4.0	4.6	5.0	5.2	6.0	7.0	8.0	9.0	10.0	12.0	
	許容差	0 -0.4			0 -0.5			0 -0.6			0 -0.7	
k+f	基準寸法	1.60	1.85	2.00	2.10	2.45	2.80	3.20	3.55	4.00	4.80	
	許容差	0 -0.4			0 -0.5			0 -0.6			0 -0.6	
十字穴	m	参考	2.4	2.7	2.9	2.9	3.8	4.3	4.7	5.1	6.9	
	Q	最大	1.21	1.52	1.72	1.72	1.63	2.13	2.53	2.93	3.13	3.46
		最小	0.85	1.14	1.34	1.34	1.11	1.60	1.99	2.38	2.58	2.90
	十字穴の番号	1				2				3		
d	最大	1.98	2.28	2.48	2.58	2.98	3.47	3.978	4.47	4.976	5.97	
	最小	1.89	2.19	2.38	2.48	2.874	3.36	3.838	4.34	4.826	5.82	
P(ピッチ)		0.4	0.4	0.45	0.45	0.5	0.6	0.7	0.75	0.8	1.0	

4.0			
長さ	入り数	生地	SSC304
8	2000×18	●	●
10	1000×20	●	●
10	2000×18		●
12	1000×24	●	●
16	1000×18	●	●
20	500×24	●	

5.0		
長さ	入り数	生地
16	500×18	●

⊕ トラストタッピンねじ(3種溝なし C-0形)




22000103

鉄

22020103

ステンレス

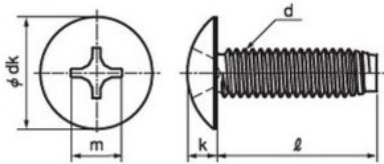

呼び径		2	2.3	2.5	2.6	3	3.5	4	4.5	5	6	
dk	基準寸法	4.5	5.2	5.7	5.9	6.9	8.1	9.4	10.6	11.8	14.0	
	許容差	0 -0.4			0 -0.5			0 -0.6			0 -0.7	
k	基準寸法	1.20	1.40	1.50	1.60	1.90	2.20	2.50	2.80	3.10	3.70	
	許容差	±0.1				±0.15				±0.2		
十字穴	m	参考	2.2	2.4	2.5	2.6	2.9	4.0	4.3	4.7	6.3	
	Q	最大	1.01	1.21	1.32	1.42	1.72	1.83	2.13	2.53	2.83	2.86
		最小	0.65	0.85	0.95	1.05	1.34	1.30	1.60	1.99	2.29	2.31
	十字穴の番号	1				2				3		
d	最大	1.98	2.28	2.48	2.58	2.98	3.47	3.978	4.47	4.976	5.97	
	最小	1.89	2.19	2.38	2.48	2.874	3.36	3.838	4.34	4.826	5.82	
P(ピッチ)		0.4	0.4	0.45	0.45	0.5	0.6	0.7	0.75	0.8	1.0	

3.0		
長さ	入り数	ステンレス
6	2000×24	●
8	2000×20	●

		M4.0														
長さ	入り数	鉄												ステンレス		
		クロメート	三層クロメート	三層クロメート	ニッケル	クローム	亜鉛黒	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	SSC304	SSC316
6	1000×24													●	●	
8	1000×24													●	●	●
8	1500×14	●												●	●	●
10	1000×18													●	●	●
10	1200×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×18													●	●	●
12	1200×14		●	●	●	●	●	●	●	●	●	●	●	●	●	●
14	500×24													●	●	●
16	500×24													●	●	●
18	500×24													●	●	●
20	500×24													●	●	●
25	500×18													●	●	●
30	500×18													●	●	●
35	500×15													●	●	●

		M5.0															
長さ	入り数	鉄												ステンレス			
		クロメート	三層クロメート	三層クロメート	ニッケル	クローム	亜鉛黒	メッキ	メッキ	メッキ	メッキ	メッキ	メッキ	生地	SSC304	SSC316	
8	500×24														●	●	
10	500×24														●	●	●
12	500×18														●	●	●
12	700×14	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	
14	500×18														●	●	●
16	500×14	●													●	●	●
16	500×18														●	●	●
18	500×18														●	●	●
20	400×18														●	●	●
25	200×24														●	●	●
30	200×24														●	●	●
35	200×18														●	●	●
40	200×18														●	●	●