


# サンコータイト ⊕ Sタイプ Ⅲ



小ねじ  
マフクロねじ  
組込みねじ  
タッピンねじ  
タップタイト・ハイテクねじ  
いたすら防止ねじ  
建材用スクリーナー  
ボルト  
キャップ・ボロ  
ドリルねじ  
座金  
つまみねじ  
ナット  
樹脂製品  
アンカーボルト

30000001 鉄	30020001 ステンレス	30030001 SUS 410
---------------	-------------------	---------------------

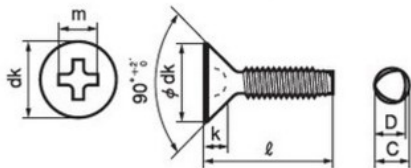

ねじの呼び	ピッチ	dk		k		十字穴			ねじ径					
		基準寸法	許容差	基準寸法	許容差	m	Q		十字穴	C		D		
							最大	最小		最大	最小	最大	最小	
2	0.4	4.0	0 -0.4	1.20	0 -0.2	2.2	1.01	0.65	1	2.03	1.95	1.95	1.87	
2.3	0.4	4.6		1.35		2.4	1.21	0.85		2.33	2.25	2.25	2.17	
2.5	0.45	5		1.45		2.6	1.42	1.05		2.55	2.47	2.46	2.38	
2.6	0.45	5.2	1.50	2.6	1.42	1.05	2.64	2.56		2.55	2.47			
3	0.5	6.0	0 -0.5	1.75	0 -0.3	3.6	1.43	0.91		2	3.04	2.96	2.94	2.86
3.5	0.6	7.0		2.00		4.1	1.93	1.40			3.55	3.47	3.43	3.35
4	0.7	8.0		2.30		4.5	2.33	1.79	4.06		3.98	3.92	3.84	
5	0.8	10.0	0 -0.6	2.80	0 -0.4	5.1	2.93	2.38	3		5.08	5	4.92	4.84
6	1.0	12.0	0 -0.7	3.40		6.7	3.26	2.70			6.10	6.00	5.90	5.80

2.0		鉄											
長さ	入り数	鉄											
		コテロ	クロメイト	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ワザル	ステンレス	ステンレス	ステンレス	ステンレス
5	20000×10	●	●	●	●	●	●	●	●	●	●	●	●
6	18000×10	●	●	●	●	●	●	●	●	●	●	●	●
8	14000×10	●	●	●	●	●	●	●	●	●	●	●	●
10	10000×10	●	●	●	●	●	●	●	●	●	●	●	●

2.5		鉄											
長さ	入り数	鉄											
		コテロ	クロメイト	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ワザル	ステンレス	ステンレス	ステンレス	ステンレス
6	10000×10	●	●	●	●	●	●	●	●	●	●	●	●
8	8000×10	●	●	●	●	●	●	●	●	●	●	●	●
10	7000×10	●	●	●	●	●	●	●	●	●	●	●	●
12	6000×10	●	●	●	●	●	●	●	●	●	●	●	●

2.6		鉄											
長さ	入り数	鉄											
		コテロ	クロメイト	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ワザル	ステンレス	ステンレス	ステンレス	ステンレス
5	12000×10	●	●	●	●	●	●	●	●	●	●	●	●
6	10000×10	●	●	●	●	●	●	●	●	●	●	●	●
8	8000×10	●	●	●	●	●	●	●	●	●	●	●	●
10	7000×10	●	●	●	●	●	●	●	●	●	●	●	●

3.0		鉄												ステンレス
長さ	入り数	鉄												ステンレス
		コテロ	クロメイト	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ワザル	ステンレス	ステンレス	ステンレス	ステンレス	
5	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
6	3000×20													●
6	8000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
8	2000×20													●
8	6000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
10	2000×20													●
10	5000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1500×20													●
12	4000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
14	3500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
16	3000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
20	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●

4.0		鉄												SUS 410
長さ	入り数	鉄												SUS 410
		コテロ	クロメイト	三価ホウ酸	三価フッ素	ニッケル	クロム	亜鉛黒	黒ワザル	ステンレス	ステンレス	ステンレス	ステンレス	
8	1200×20													●
8	3500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
10	1200×20													●
10	2500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
12	1000×20													●
12	2500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
14	2000×10	●	●	●	●	●	●	●	●	●	●	●	●	●
15	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
16	1500×10	●	●	●	●	●	●	●	●	●	●	●	●	●
20	1200×10	●	●	●	●	●	●	●	●	●	●	●	●	●
25	1000×10	●	●	●	●	●	●	●	●	●	●	●	●	●

5.0		鉄		
長さ	入り数	鉄		
		三価ホウ酸	三価フッ素	ニッケル
10	1000×10	●	●	●
12	900×10	●	●	●
16	800×10	●	●	●
20	800×10	●	●	●

6.0		鉄		
長さ	入り数	鉄		
		三価ホウ酸	三価フッ素	ニッケル
12	600×10	●	●	●
14	600×10	●	●	●
16	600×10	●	●	●
20	500×10	●	●	●
25	500×10	●	●	●
30	400×10	●	●	●